

## Han Brid-USB-M Patchkabel

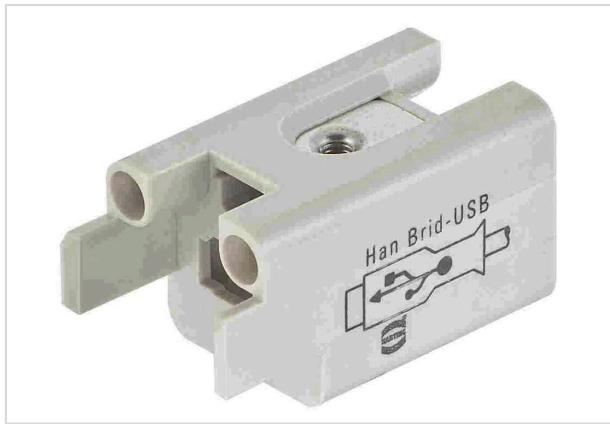


Image is for illustration purposes only. Please refer to product description.

Part number	09 12 001 3091
Specification	Han Brid-USB-M Patchkabel
HARTING eCatalogue	<a href="https://harting.com/09120013091">https://harting.com/09120013091</a>

### Identification

Category	Inserts
Series	Han-Brid®
Identification	Han-Brid® USB

### Version

Gender	Female
Size	3 A
Number of contacts	2
further contacts	+ USB
Details	Cable side

### Technical characteristics

Rated current	1 A
Rated voltage	50 V
Rated impulse voltage	0.8 kV
Pollution degree	3
Insulation resistance	$>10^{10} \Omega$
Contact resistance	$\geq 4 \text{ m}\Omega$
Limiting temperature	-40 ... +85 °C
Mating cycles	$\geq 500$

### Material properties

Material (insert)	Polycarbonate (PC)
-------------------	--------------------

## Material properties

Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel

## Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
UL / CSA	UL 1977 ECBT2.E235076 CSA-C22.2 No. 182.3 ECBT8.E235076

## Commercial data

Packaging size	1
Net weight	7.5 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140016514
eCl@ss	27440205 Contact insert for industrial connectors
ETIM	EC000438
UNSPSC 24.0	39121522