

Han pneumatic module for 2 contact, fe

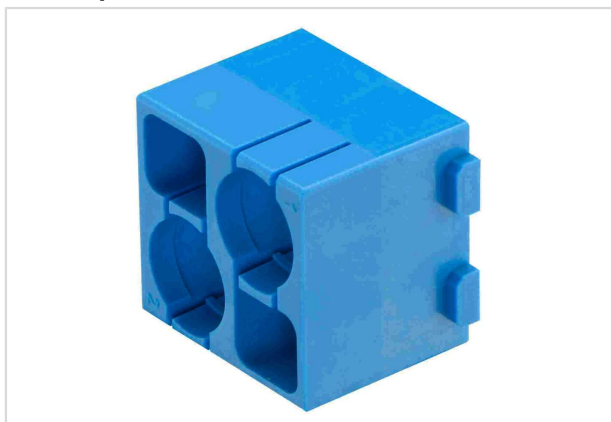


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 002 3502
Specification	Han pneumatic module for 2 contact, fe
HARTING eCatalogue	https://harting.com/09140023502

Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® Pneumatic module
Size of the module	Single module

Version

Gender	Female
Number of contacts	2
Details	Please order contacts separately.

Technical characteristics

Limiting temperature	-40 ... +85 °C
Mating cycles	≥10,000

Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	Blue
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained



Pushing Performance
Since 1945

Material properties

REACH SVHC substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R22 (HL 1-3)
	R23 (HL 1-3)

Specifications and approvals

Specifications	IEC 61984
	IEC 60664-1

Commercial data

Packaging size	2
Net weight	12.385 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140184879
eCl@ss	27440220 Module for industrial connectors (pneumatic)
ETIM	EC000438
UNSPSC 24.0	39121552