

## Han SC module, female with 4 ferrules

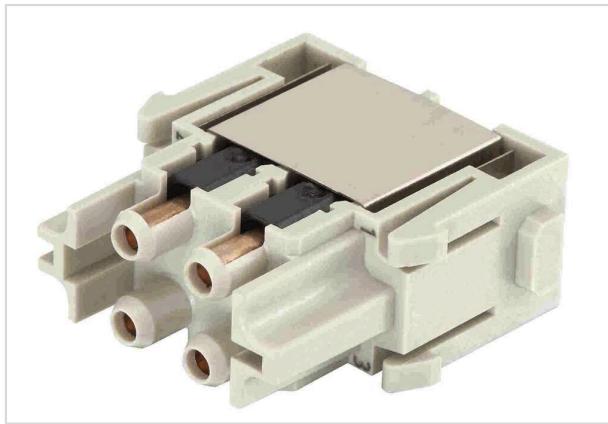


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 004 4711
Specification	Han SC module, female with 4 ferrules
HARTING eCatalogue	<a href="https://harting.com/09140044711">https://harting.com/09140044711</a>

### Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® SC module
Size of the module	Single module
Description of the module	with ceramic ferrule

### Version

Gender	Female
Number of contacts	4
Details	Please order contacts separately. Please order fixing plate separately.

### Technical characteristics

Limiting temperature	-40 ... +85 °C
Mating cycles	≥500

### Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption

## Material properties

China RoHS	50
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Lead
ECHA SCIP number	5dbb3851-b94e-4e88-97a1-571845975242
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

## Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076
Approvals	DNV GL

## Commercial data

Packaging size	2
Net weight	6.789 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140020207
eCl@ss	27440219 Module for industrial connectors (FO)
ETIM	EC000438
UNSPSC 24.0	39121552