

## Han SC module, female with metal ferrule

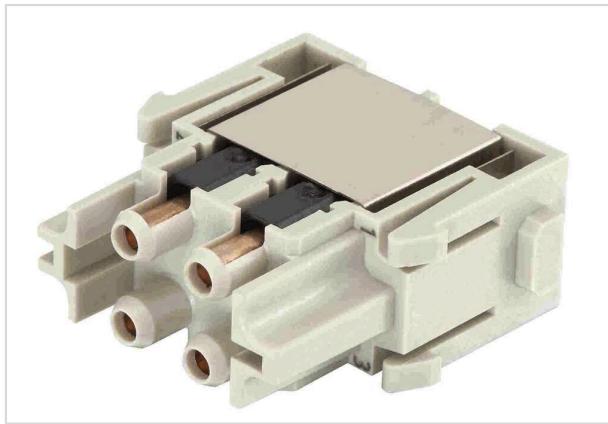


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 004 4713
Specification	Han SC module, female with metal ferrule
HARTING eCatalogue	<a href="https://harting.com/09140044713">https://harting.com/09140044713</a>

### Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® SC module
Size of the module	Single module
Description of the module	with metal ferrule

### Version

Gender	Female
Number of contacts	4
Details	Please order contacts separately. Please order fixing plate separately.

### Technical characteristics

Limiting temperature	-40 ... +85 °C
Mating cycles	≥500

### Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e

## Material properties

REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

## Specifications and approvals

Approvals	DNV GL
-----------	--------

## Commercial data

Packaging size	2
Net weight	11.875 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140020221
eCl@ss	27440219 Module for industrial connectors (FO)
ETIM	EC000438
UNSPSC 24.0	39121552