

## Docking frame for 2 modules, float mount

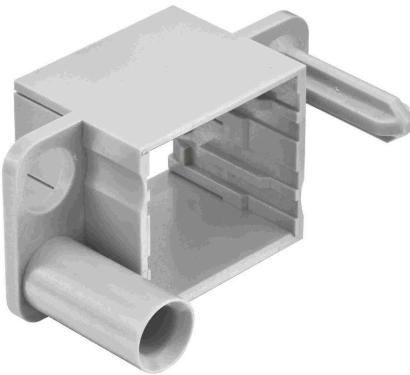


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 006 1701
Specification	Docking frame for 2 modules, float mount
HARTING eCatalogue	<a href="https://harting.com/09140061701">https://harting.com/09140061701</a>

### Identification

Category	Accessories
Series	Han-Modular®
Type of accessory	Docking frame
Description of the accessory	Float mount for 2 modules A ... B

### Technical characteristics

Limiting temperature	-40 ... +125 °C
Mating cycles	≥10,000
Note on the mating cycles	Mating cycles with other HMC components
Degree of protection acc. to IEC 60529	IP20
Floating tolerance	±2 mm
Lock-in range	±4 mm

### Material properties

Material	Polycarbonate (PC)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained

## Material properties

Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

## Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
----------------	--------------------------

## Commercial data

Packaging size	2
Net weight	16.73 g
Country of origin	Romania
European customs tariff number	85389099
GTIN	5713140020412
eCl@ss	27440206 Module carrier frame for industrial connectors
ETIM	EC002312
UNSPSC 24.0	39121421