

## Han Domino RJ45 cube, gender changer F.1

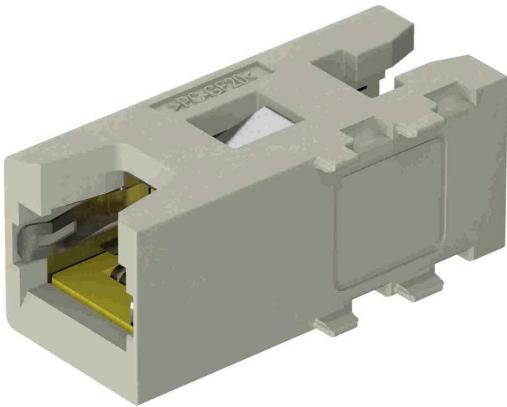


Image is for illustration purposes only. Please refer to product description.

### Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® Domino RJ45 Cube
Size of the module	Domino module
Description of the module	Gender changer for patch cable Small tab

### Version

Gender	Female
Number of contacts	8

### Technical characteristics

Rated current	1 A
Rated voltage	50 V
Rated impulse voltage	0.8 kV
Pollution degree	3
Transmission characteristics	Cat. 6A Class EA up to 500 MHz
	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
	5 Gbit/s
	10 Gbit/s
Insulation resistance	>10 <sup>10</sup> Ω

## Technical characteristics

Limiting temperature -40 ... +70 °C

Mating cycles ≥500

## Material properties

Material (insert)	Polyamide (PA) Polycarbonate (PC) Stainless steel
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

## Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
----------------	--------------------------

## Commercial data

Packaging size	2
Net weight	7 g
Country of origin	Romania
European customs tariff number	85366990
GTIN	5713140354678
eCl@ss	27440218 Module for industrial connectors (data)
ETIM	EC000438
UNSPSC 24.0	39121552