

Han Domino RJ45 cube, patch cable M2

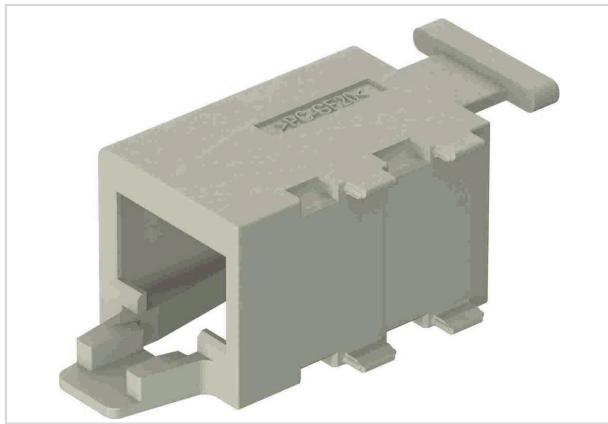


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 945 2001
Specification	Han Domino RJ45 cube, patch cable M2
HARTING eCatalogue	https://harting.com/09149452001

Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® Domino RJ45 Cube
Size of the module	Domino module
Description of the module	Adapter for patch cable Large Tab

Version

Gender	Male
--------	------

Technical characteristics

Insulation resistance	>10 ¹⁰ Ω
Limiting temperature	-40 ... +125 °C
Mating cycles	≥500

Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e

Material properties

REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Specifications and approvals

Specifications	IEC 60664-1 IEC 61984 IEC 61373 Category 1 Class B
----------------	--

Commercial data

Packaging size	2
Net weight	3.343 g
Country of origin	Romania
European customs tariff number	85366990
GTIN	5713140398276
eCl@ss	27440207 Adapter for industrial connectors (module/contact insert)
ETIM	EC002312
UNSPSC 24.0	39121469