

SEK-18 ACC.STRAIN RELIEF CLAMP FE 40P

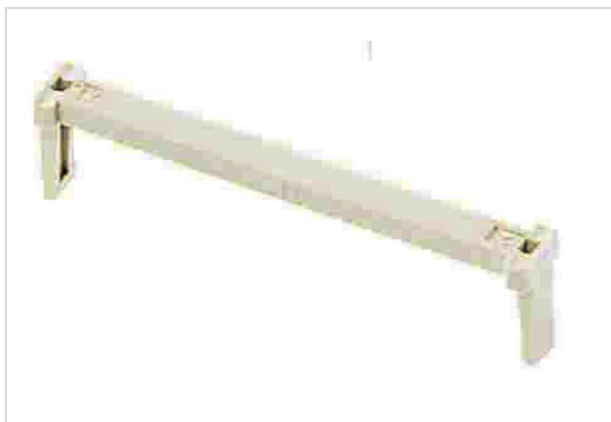


Image is for illustration purposes only. Please refer to product description.

Part number	09 18 540 9002
Specification	SEK-18 ACC.STRAIN RELIEF CLAMP FE 40P
HARTING eCatalogue	https://harting.com/09185409002

Identification

Category	Accessories
Series	SEK
Type of accessory	Strain relief clamp

Version

Size	40 poles
------	----------

Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R26

Commercial data

Packaging size	100
Net weight	1.309 g
Country of origin	Romania
European customs tariff number	85389099



Pushing Performance
Since 1945

Commercial data

GTIN	5713140033726
eCl@ss	27440292 Connector component (accessories)
ETIM	EC002943
UNSPSC 24.0	39121400
