

Han U Protect Cover Die Cast for Hood PG

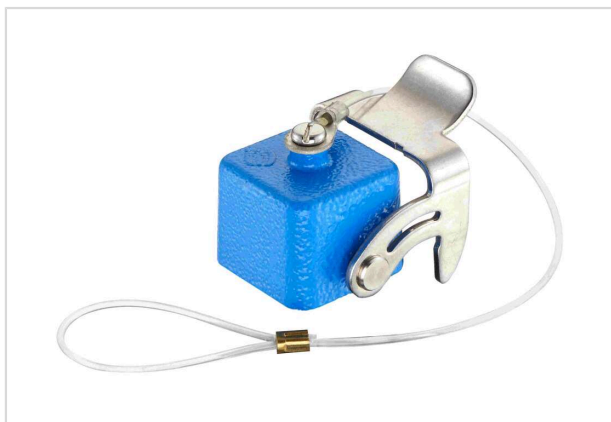


Image is for illustration purposes only. Please refer to product description.

Part number	09 36 003 5402
Specification	Han U Protect Cover Die Cast for Hood PG
HARTING eCatalogue	https://harting.com/09360035402

Identification

Category	Accessories
Series of hoods/housings	Han [®] Ex
Type of accessory	Protection cover
Description of the accessory	for hoods With fixing cord

Version

Size	3 A
Locking type	Single locking lever
Details	for mounted male insert
Details	ATTENTION! Only to be used with Han [®] Ex hoods and housings!

Technical characteristics

Limiting temperature	-20 ... +40 °C
Degree of protection acc. to IEC 60529	IP65 With cable gland

Material properties

Material (hood/housing)	Zinc die-cast
Surface (hood/housing)	Powder-coated
Colour (hood/housing)	RAL 5015 (sky blue)
Material (locking)	Steel
Surface (locking)	Zinc plated
RoHS	compliant



Pushing Performance
Since 1945

Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead
	Nickel

Commercial data

Packaging size	10
Net weight	28 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140054745
eCl@ss	27440208 Cap for industrial connectors
ETIM	EC002314
UNSPSC 24.0	39121467