

Han 3Ex-C-Metal f. HBM with seal

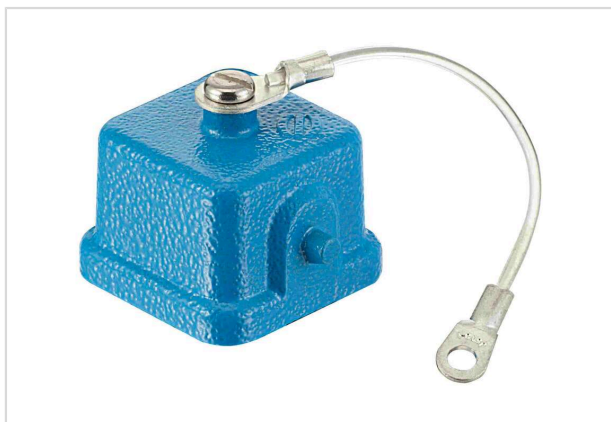


Image is for illustration purposes only. Please refer to product description.

Part number	09 36 003 5405
Specification	Han 3Ex-C-Metal f. HBM with seal
HARTING eCatalogue	https://harting.com/09360035405

Identification

Category	Accessories
Series of hoods/housings	Han® Ex
Type of accessory	Protection cover
Description of the accessory	for bulkhead mounted housings
	for surface mounted housings
	With fixing cord
	With seal

Version

Size	3 A
Locking type	Single locking lever
Details	for mounted female insert
Details	ATTENTION! Only to be used with Han® Ex hoods and housings!

Technical characteristics

Limiting temperature	-20 ... +40 °C
Degree of protection acc. to IEC 60529	IP65

Material properties

Material (hood/housing)	Zinc die-cast
Surface (hood/housing)	Powder-coated
Colour (hood/housing)	RAL 5015 (sky blue)
Material (seal)	NBR
RoHS	compliant



Pushing Performance
Since 1945

Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

Commercial data

Packaging size	10
Net weight	22.7 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140054752
eCl@ss	27440208 Cap for industrial connectors
ETIM	EC002314
UNSPSC 24.0	39121467