

Frame Han 24HPR EasyCon hood f. st. ins.

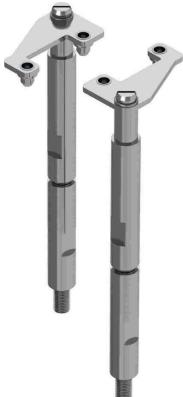


Image is for illustration purposes only. Please refer to product description.

Part number	09 40 024 9941
Specification	Frame Han 24HPR EasyCon hood f. st. ins.
HARTING eCatalogue	https://harting.com/09400249941

Identification

Category	Accessories
Series of hoods/housings	Han® HPR EasyCon
Type of accessory	Frame
Description of the accessory	for standard inserts for Han-Modular® hinged frames

Version

Gender	Male Female
Size	24 B
Pack contents	2x M4/M5 distance bolts (AF 7) 2x M5/M6 distance bolts (AF 7) 2x M4 screw 2x washer SK S4

Technical characteristics

Tightening torque	1.5 Nm Fixing screws M4 6 Nm Distance bolt
Mating cycles	≥100

Material properties

Material (accessories)	Stainless steel
RoHS	compliant
ELV status	compliant
China RoHS	e

Material properties

REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel

Commercial data

Packaging size	1
Net weight	148.1 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140194274
eCl@ss	27440210 Fixing element for industrial connectors
ETIM	EC002310
UNSPSC 24.0	39121466