

HPP V4 RJ45 Cat5 EI-PFT 8p, metal

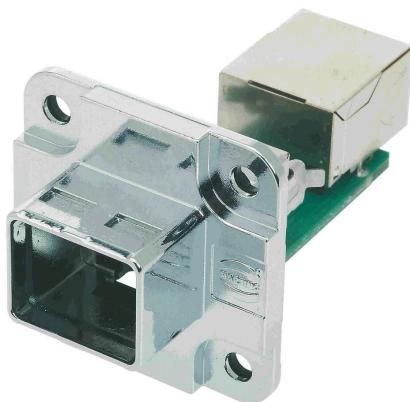


Image is for illustration purposes only. Please refer to product description.

| | |
|--------------------|---|
| Part number | 09 45 295 1130 |
| Specification | HPP V4 RJ45 Cat5 EI-PFT 8p, metal |
| HARTING eCatalogue | https://harting.com/09452951130 |

Identification

| | |
|-----------------------------|-------------------------------|
| Category | Connectors |
| Series | HARTING PushPull (V4) RJ45 |
| Element | Panel feed trough set |
| Type of hood/housing | Bulkhead mounted housing |
| Description of hood/housing | Easy Install |

Version

| | |
|--------------------|--|
| Shielding | Fully shielded, 360° shielding contact |
| Number of contacts | 5 |
| Locking type | PushPull |
| Pack contents | incl. integrated seal, 2x RJ45-jack and board drillings for M3 |

Technical characteristics

| | |
|--|-------------------------------------|
| Transmission characteristics | Cat. 5 Class D up to 100 MHz |
| Data rate | 10 Mbit/s 100 Mbit/s 1 Gbit/s |
| Limiting temperature | -40 ... +70 °C |
| Mating cycles | ≥750 |
| Degree of protection acc. to IEC 60529 | IP65 |

Material properties

| | |
|-------------------------|---------------|
| Material (hood/housing) | Zinc die-cast |
|-------------------------|---------------|

Material properties

| | |
|---|----------------|
| Colour (hood/housing) | silver |
| Material flammability class acc. to UL 94 | V-0 |
| RoHS | compliant |
| ELV status | compliant |
| China RoHS | e |
| REACH Annex XVII substances | Not contained |
| REACH ANNEX XIV substances | Not contained |
| REACH SVHC substances | Not contained |
| California Proposition 65 substances | Yes |
| California Proposition 65 substances | Lead Nickel |

Specifications and approvals

| | |
|----------------|--------------------------------|
| Specifications | IEC 61076-3-106 Variant 4 (V4) |
| Approvals | DNV GL |

Commercial data

| | |
|--------------------------------|---|
| Packaging size | 1 |
| Net weight | 33.5 g |
| Country of origin | Romania |
| European customs tariff number | 85366990 |
| GTIN | 5713140059931 |
| eCl@ss | 27440114 Rectangular connector (for field assembly) |
| ETIM | EC002636 |
| UNSPSC 24.0 | 39121408 |