

RJI RJ45 coupler PCB 2x RJ45 str.+angl.

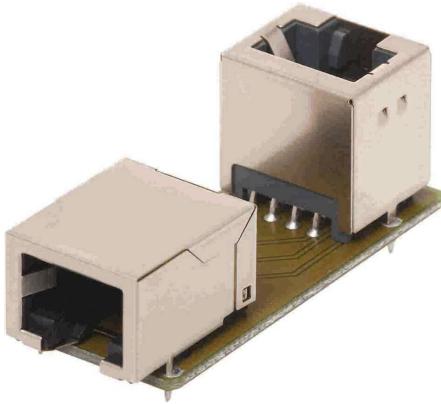


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 545 1138
Specification	RJI RJ45 coupler PCB 2x RJ45 str.+angl.
HARTING eCatalogue	https://b2b.harting.com/09455451138

Identification

Category	Connectors
Series	HARTING RJ Industrial®
Element	Coupler
Specification	RJ45

Version

Shielding	Fully shielded, 360° shielding contact
Number of contacts	8

Technical characteristics

Rated current	1.5 A
Rated voltage	125 V
Mating cycles	≥750
Degree of protection acc. to IEC 60529	IP20

Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained

Specifications and approvals

Approvals	DNV GL
-----------	--------

Commercial data

Packaging size	1
Net weight	15.45 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140061217
ETIM	EC001264
eCl@ss	27440190 Industry connector (unspecified)