

HARTING IE Cat.6A 4x2xAWG26/7 PUR, 100m

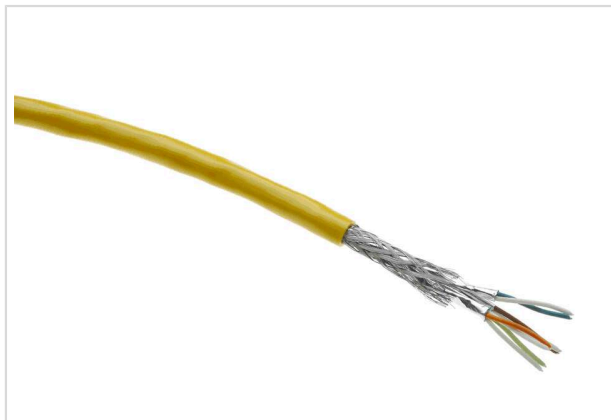


Image is for illustration purposes only. Please refer to product description.

| | |
|--------------------|---|
| Part number | 09 45 600 0600 |
| Specification | HARTING IE Cat.6A 4x2xAWG26/7 PUR, 100m |
| HARTING eCatalogue | https://harting.com/09456000600 |

Identification

| | |
|---------------|----------------------|
| Category | System cabling |
| Element | Bulk cables |
| Specification | Not assembled |
| Type of cable | Copper cable (round) |

Version

| | |
|-----------------|----------------|
| Cable length | 100 m |
| Number of cores | 8 |
| Core structure | 4x 2x AWG 26/7 |

Technical characteristics

| | |
|-------------------------------|--|
| Transmission characteristics | Cat. 6 _A Class E _A up to 500 MHz |
| Data rate | 10 Mbit/s |
| | 100 Mbit/s |
| | 1 Gbit/s |
| | 2.5 Gbit/s |
| | 5 Gbit/s |
| Limiting temperature | -40 ... +80 °C unmoved |
| | -40 ... +80 °C moved |
| Minimum bending radius | 10x Cable diameter (repeated bending) |
| | 5x Cable diameter (singular bending) |
| Conductor resistance @ 20 °C | ≤290 Ω/km |
| Insulation resistance @ 20 °C | ≥500 MΩ x km |
| Signal run time @ 20 °C | ≤5.13 ns/m |



Pushing Performance
Since 1945

Technical characteristics

Impedance @ 100 MHz 100 Ω \pm 5 %

Material properties

| | |
|--------------------------------------|--------------------|
| Material (cable) | PUR (polyurethane) |
| Colour (cable) | Yellow |
| RoHS | compliant |
| ELV status | compliant |
| China RoHS | e |
| REACH Annex XVII substances | Not contained |
| REACH ANNEX XIV substances | Not contained |
| REACH SVHC substances | Not contained |
| California Proposition 65 substances | Not contained |

Specifications and approvals

| | |
|----------------|--|
| Specifications | UN/ECE-R 118 fire protection for rolling stock |
| UL / CSA | UL 21815 AVLV2.E333435 |

Commercial data

| | |
|--------------------------------|--|
| Packaging size | 1 |
| Net weight | 4,100 g |
| Country of origin | Germany |
| European customs tariff number | 85444995 |
| GTIN | 5713140062153 |
| eCl@ss | 27061801 Data and communication cable (copper) |
| ETIM | EC003249 |
| UNSPSC 24.0 | 26121609 |