

## RJ45 Han3A met. PN Cat5 PUR 1.5m

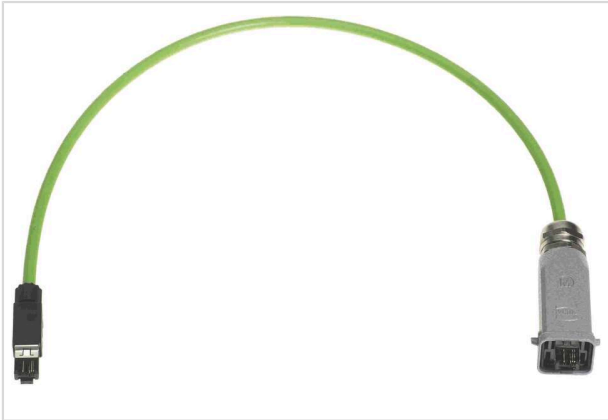


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 700 0023
Specification	RJ45 Han3A met. PN Cat5 PUR 1.5m
HARTING eCatalogue	<a href="https://harting.com/09457000023">https://harting.com/09457000023</a>

### Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	RJ45
Connector 2	Han <sup>®</sup> 3 A Metal
Type of cable	Copper cable (round)

### Version

Cable length	1.5 m
Number of cores	4
Core structure	4x AWG 22/7

### Technical characteristics

Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s
Limiting temperature	-40 ... +70 °C

### Material properties

Material (cable)	PUR (polyurethane)
Colour (cable)	Green
RoHS	compliant



**Pushing Performance**  
Since 1945

## Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

## Specifications and approvals

PROFINET	Yes
----------	-----

## Commercial data

Packaging size	2
Net weight	231 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140267800
eCl@ss	27060390 Ready-made data cable (unspecified)
ETIM	EC002599
UNSPSC 24.0	26121600