

RJ45 cab IP20/M12 4XAWG22/7; trail.; 5,0m

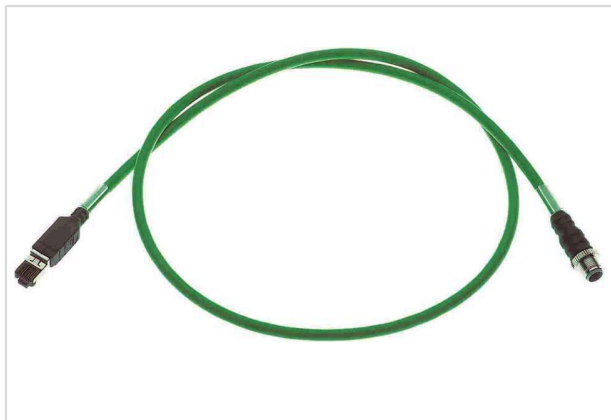


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 700 5027
Specification	RJ45 cab IP20/M12 4XAWG22/7; trail.; 5,0m
HARTING eCatalogue	https://harting.com/09457005027

Identification

Category	System cabling
Series	RJ45 Circular connectors M12
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	RJ45
Connector 2	M12 D-coding Male
Type of cable	Copper cable (round)

Version

Cable length	5 m
Number of cores	4
Core structure	4x AWG 22/7
Coding	D-coding

Technical characteristics

Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s
Limiting temperature	-30 ... +70 °C

Material properties

Material (cable)	PUR (polyurethane)
------------------	--------------------



Pushing Performance
Since 1945

Material properties

Colour (cable)	Green
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

Specifications and approvals

Specifications	UN/ECE-R 118 fire protection for rolling stock
----------------	--

Commercial data

Packaging size	1
Net weight	351.32 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140062467
eCl@ss	27060390 Ready-made data cable (unspecified)
ETIM	EC002599
UNSPSC 24.0	26121600