

## RJ45 cab IP20/M12 4XAWG22/7; trail.; 8,0m

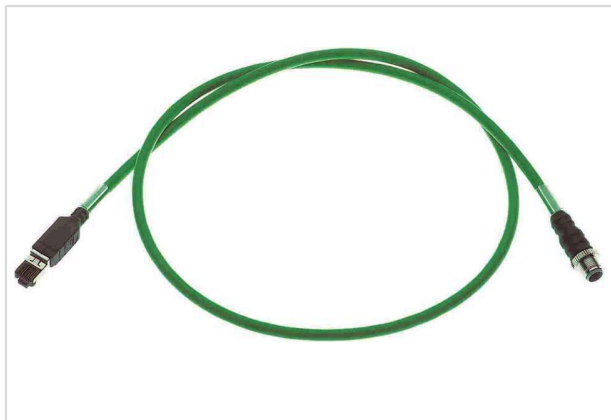


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 700 5030
Specification	RJ45 cab IP20/M12 4XAWG22/7; trail.; 8,0m
HARTING eCatalogue	<a href="https://harting.com/09457005030">https://harting.com/09457005030</a>

### Identification

Category	System cabling
Series	RJ45 Circular connectors M12
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	RJ45
Connector 2	M12 D-coding Male
Type of cable	Copper cable (round)

### Version

Cable length	8 m
Number of cores	4
Core structure	4x AWG 22/7
Coding	D-coding

### Technical characteristics

Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s
Limiting temperature	-30 ... +70 °C

### Material properties

Material (cable)	PUR (polyurethane)
------------------	--------------------



**Pushing Performance**  
Since 1945

## Material properties

Colour (cable)	Green
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel

## Specifications and approvals

Specifications	UN/ECE-R 118 fire protection for rolling stock
----------------	--

## Commercial data

Packaging size	1
Net weight	547.5 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140268289
eCl@ss	27060390 Ready-made data cable (unspecified)
ETIM	EC002599
UNSPSC 24.0	26121600