

## RJI RJ45 Han3A met. CAT6 PUR 10m

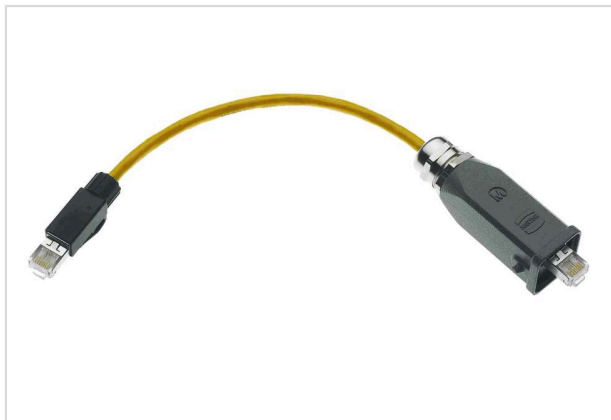


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 701 1543
Specification	RJI RJ45 Han3A met. CAT6 PUR 10m
HARTING eCatalogue	<a href="https://harting.com/09457011543">https://harting.com/09457011543</a>

### Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	RJ45
Connector 2	Han <sup>®</sup> 3 A Metal
Type of cable	Copper cable (round)

### Version

Cable length	10 m
Number of cores	8
Core structure	4x 2x AWG 26/7

### Technical characteristics

Transmission characteristics	Cat. 6 <sub>A</sub> Class E <sub>A</sub> up to 500 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
	5 Gbit/s
	10 Gbit/s
Limiting temperature	-10 ... +70 °C

### Material properties

Material (cable)	PUR (polyurethane)
------------------	--------------------



Pushing Performance  
Since 1945

## Material properties

Colour (cable)	Yellow
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol Potassium 1,1,2,2,3,3,4,4,4-nonafluorobutane-1-sulphonate Lead
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

## Commercial data

Packaging size	1
Net weight	580 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140267718
eCl@ss	27060390 Ready-made data cable (unspecified)
ETIM	EC002599
UNSPSC 24.0	26121600