

RJ45 Han3A met.Hyb. PN Cat5+4x1,5 15m

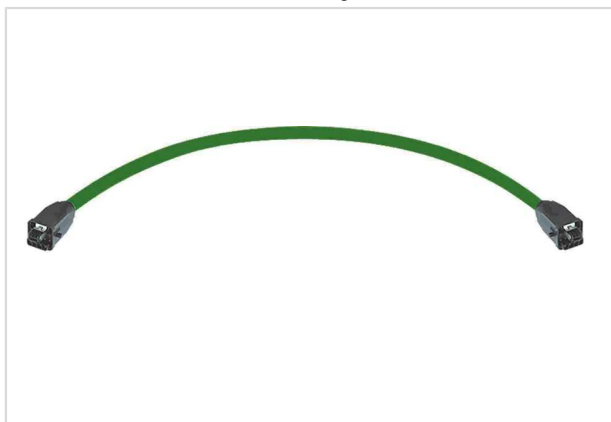


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 715 1374
Specification	RJ45 Han3A met.Hyb. PN Cat5+4x1,5 15m
HARTING eCatalogue	https://harting.com/09457151374

Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	Han [®] 3 A Hybrid Metal
Connector 2	Han [®] 3 A Hybrid Metal
Type of cable	Copper cable (round)

Version

Cable length	15 m
Number of cores	8
Core structure	4x AWG 22/7 4x 1.5 mm ²

Technical characteristics

Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s

Material properties

Material (cable)	FRNC (LSZH)
Colour (cable)	Green



Pushing Performance
Since 1945

Material properties

RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol Lead
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

Commercial data

Packaging size	1
Net weight	2,655 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140249820
eCl@ss	27060390 Ready-made data cable (unspecified)
ETIM	EC002599
UNSPSC 24.0	26121600