



Pushing Performance
Since 1945

RJ45 Han3A met. Cat6A PVC 5.0m

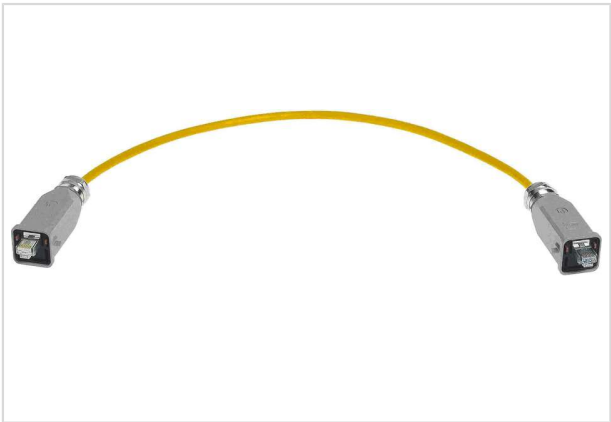


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 715 1527
Specification	RJ45 Han3A met. Cat6A PVC 5.0m
HARTING eCatalogue	https://harting.com/09457151527

Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	Han [®] 3 A Metal
Connector 2	Han [®] 3 A Metal
Type of cable	Copper cable (round)

Version

Cable length	5 m
Number of cores	8
Core structure	4x 2x AWG 26/7

Technical characteristics

Transmission characteristics	Cat. 6 _A Class E _A up to 500 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
	5 Gbit/s
Limiting temperature	10 Gbit/s
	-10 ... +70 °C

Material properties

Material (cable)	PVC
------------------	-----



Pushing Performance
Since 1945

Material properties

Colour (cable)	Yellow
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol
	Potassium 1,1,2,2,3,3,4,4,4-nonafluorobutane-1-sulphonate
	Lead
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead
	Nickel

Commercial data

Packaging size	1
Net weight	465.8 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140063037
eCl@ss	27060390 Ready-made data cable (unspecified)
ETIM	EC002599
UNSPSC 24.0	26121600