

RJ45 Han3A pla.Hyb. PN Cat5+4x1,5 3.0m

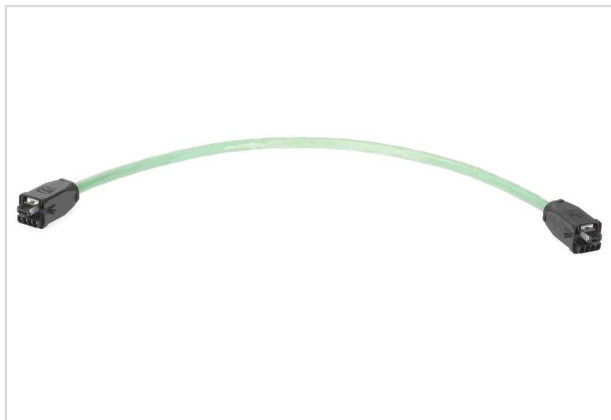


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 725 1325
Specification	RJ45 Han3A pla.Hyb. PN Cat5+4x1,5 3.0m
HARTING eCatalogue	https://harting.com/09457251325

Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	Han® 3 A Hybrid Thermoplastic
Connector 2	Han® 3 A Hybrid Thermoplastic
Type of cable	Copper cable (round)

Version

Cable length	3 m
Number of cores	8
Core structure	4x AWG 22/7 4x 1.5 mm ²

Technical characteristics

Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s
Limiting temperature	-20 ... +70 °C

Material properties

Material (cable)	FRNC (LSZH)
------------------	-------------



Pushing Performance
Since 1945

Material properties

Colour (cable)	Green
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Specifications and approvals

PROFINET	Yes
----------	-----

Commercial data

Packaging size	1
Net weight	562 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140063082
eCl@ss	27060390 Ready-made data cable (unspecified)
ETIM	EC002599
UNSPSC 24.0	26121600