

## RJ45 Han3A pla.Hyb. PN Cat5+4x1,5 5.0m

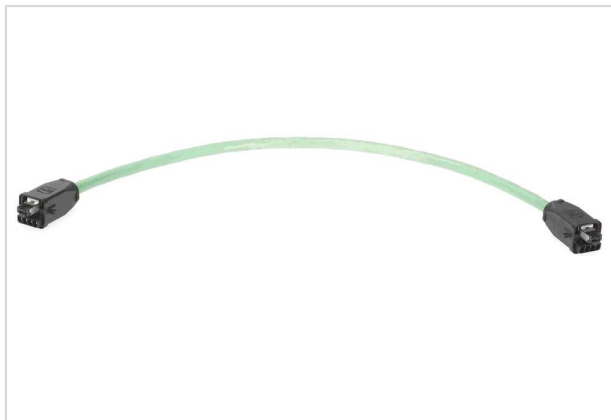


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 725 1327
Specification	RJ45 Han3A pla.Hyb. PN Cat5+4x1,5 5.0m
HARTING eCatalogue	<a href="https://harting.com/09457251327">https://harting.com/09457251327</a>

### Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	Han <sup>®</sup> 3 A Hybrid Thermoplastic
Connector 2	Han <sup>®</sup> 3 A Hybrid Thermoplastic
Type of cable	Copper cable (round)

### Version

Cable length	5 m
Number of cores	8
Core structure	4x AWG 22/7 4x 1.5 mm <sup>2</sup>

### Technical characteristics

Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s
Limiting temperature	-20 ... +70 °C

### Material properties

Material (cable)	FRNC (LSZH)
------------------	-------------



**Pushing Performance**  
Since 1945

## Material properties

Colour (cable)	Green
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

## Specifications and approvals

PROFINET	Yes
----------	-----

## Commercial data

Packaging size	1
Net weight	876 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140063099
eCl@ss	27060390 Ready-made data cable (unspecified)
ETIM	EC002599
UNSPSC 24.0	26121600