

## RJ45 CAT5 8P MA DE BK CABLE ASSY, 0,5M

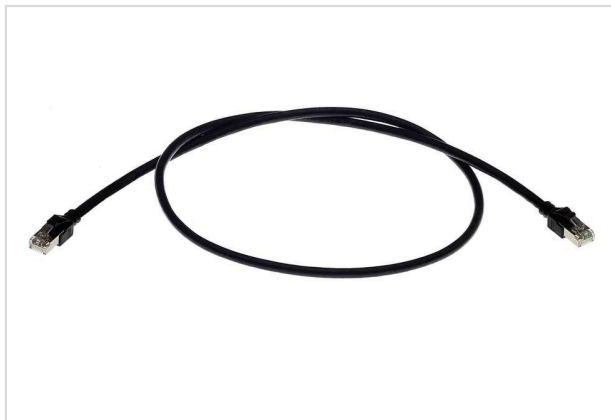


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 971 1121
Specification	RJ45 CAT5 8P MA DE BK CABLE ASSY, 0,5M
HARTING eCatalogue	<a href="https://harting.com/09459711121">https://harting.com/09459711121</a>

### Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING RJ Industrial®
Connector 2	HARTING RJ Industrial®
Type of cable	Copper cable (round)

### Version

Cable length	0.5 m
Number of cores	8
Core structure	8x AWG 26/7

### Technical characteristics

Transmission characteristics	Cat. 5e Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s 1 Gbit/s

### Material properties

Material (cable)	PUR (polyurethane)
Colour (cable)	Black
RoHS	compliant
ELV status	compliant



**Pushing Performance**  
Since 1945

## Material properties

China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained

## Specifications and approvals

Approvals	CE
-----------	----

## Commercial data

Packaging size	1
Net weight	40 g
Country of origin	Vietnam
European customs tariff number	85444290
GTIN	5713140065130
eCl@ss	27060308 Patch cord copper (data cable)
UNSPSC 24.0	26121609