

RJl cord 4AWG22/7traï,RJ45/M12overm;5,0m

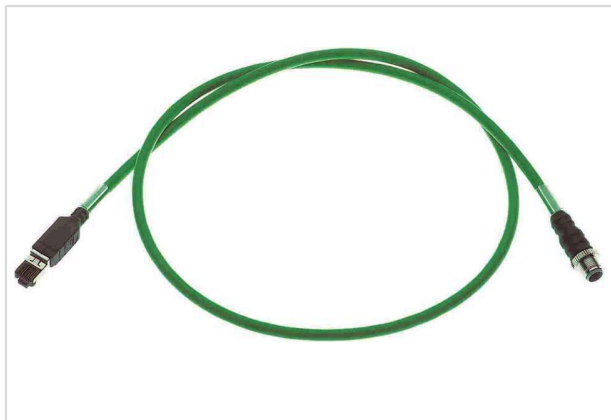


Image is for illustration purposes only. Please refer to product description.

Part number	09 47 220 2007 018
Specification	RJl cord 4AWG22/7traï,RJ45/ M12overm;5,0m
HARTING eCatalogue	https://harting.com/09472202007018

Identification

Category	System cabling
Series	RJ45 Circular connectors M12
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	RJ45
Connector 2	M12 D-coding Male
Type of cable	Copper cable (round)

Version

Cable length	5 m
Number of cores	4
Core structure	4x AWG 22/7
Coding	D-coding

Technical characteristics

Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s
Limiting temperature	-30 ... +70 °C

Material properties

Material (cable)	PUR (polyurethane)
------------------	--------------------



Pushing Performance
Since 1945

Material properties

Colour (cable)	Red
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Commercial data

Packaging size	1
Net weight	347.5 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140268685
eCl@ss	27060390 Ready-made data cable (unspecified)
ETIM	EC002599
UNSPSC 24.0	26121600