

## RJI DB Cat6a Cable Assy yellow PUR 1,5m

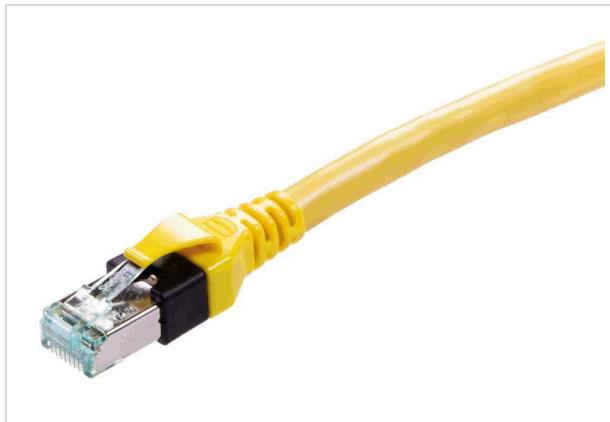


Image is for illustration purposes only. Please refer to product description.

### Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING DualBoot RJ45
Connector 2	HARTING DualBoot RJ45
Type of cable	Copper cable (round)

### Version

Cable length	1.5 m
Number of cores	8
Core structure	4x 2x AWG 26/7

### Technical characteristics

Transmission characteristics	Cat. 6A Class E <sub>A</sub> up to 500 MHz
Data rate	10 Mbit/s 100 Mbit/s 1 Gbit/s 2.5 Gbit/s 5 Gbit/s 10 Gbit/s
Limiting temperature	-40 ... +80 °C unmoved -40 ... +80 °C moved

## Material properties

Material (cable)	PUR (polyurethane)
Colour (cable)	Yellow
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	2-(2H-benzotriazol-2-yl)-4-(1,1,3,3-tetramethylbutyl)phenol (UV 329)
California Proposition 65 substances	Not contained

## Specifications and approvals

Specifications	IEC 60332-1-2 Flame retardancy IEC 60754-1 Halogen freeness EN 60811-404 Oil resistance UN/ECE-R 118 fire protection for rolling stock
UL / CSA	UL 1863 DUXR.E470046

## Commercial data

Packaging size	1
Net weight	17.29 g
Country of origin	Latvia
European customs tariff number	85444290
GTIN	5713140255531
eCl@ss	27060308 Patch cord copper (data cable)
UNSPSC 24.0	26121609