

RJ45 PROFINET cable PVC 4p; Cat. 5; 0,3m

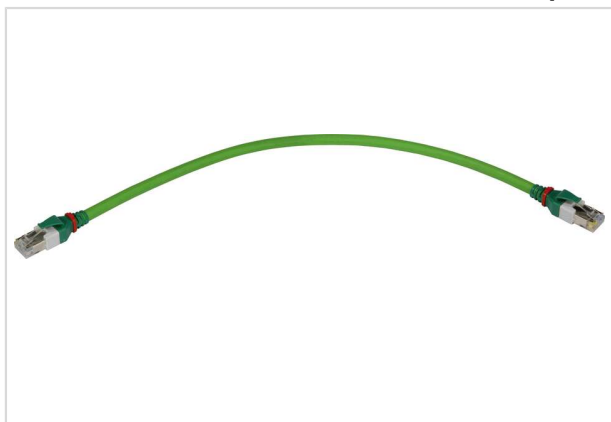


Image is for illustration purposes only. Please refer to product description.

Part number	09 48 686 8001 003
Specification	RJ45 PROFINET cable PVC 4p; Cat. 5; 0,3m
HARTING eCatalogue	https://harting.com/09486868001003

Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING DualBoot RJ45
Connector 2	HARTING DualBoot RJ45
Type of cable	Copper cable (round)
Description of the cable	Straight

Version

Cable length	0.3 m
Number of cores	4
Core structure	4x AWG 22/7

Technical characteristics

Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s
Limiting temperature	-25 ... +60 °C

Material properties

Material (cable)	PVC
------------------	-----



Pushing Performance
Since 1945

Material properties

Colour (cable)	Green
----------------	-------

Specifications and approvals

Specifications	UN/ECE-R 118 fire protection for rolling stock
----------------	--

UL / CSA	UL 1863 DUXR.E470046 Raw cable UL rating 600 V
----------	---

PROFINET	Yes
----------	-----

Commercial data

Packaging size	1
----------------	---

Net weight	0.01 g
------------	--------

Country of origin	Germany
-------------------	---------

European customs tariff number	85444290
--------------------------------	----------

GTIN	5713140392274
------	---------------

eCl@ss	27060308 Patch cord copper (data cable)
--------	---