

VB RJ45 UaD -VB RJ45 LaR Cat.6A PUR 1.5m

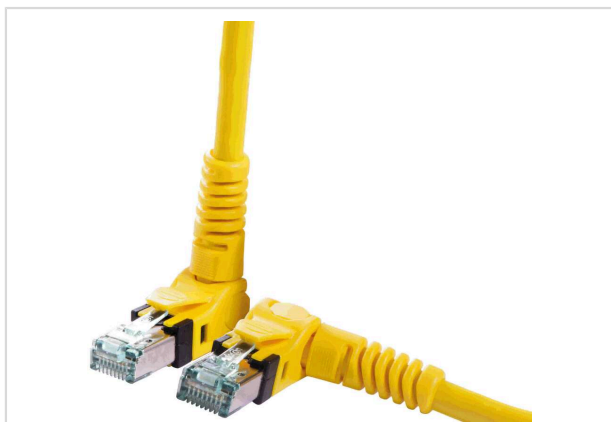


Image is for illustration purposes only. Please refer to product description.

Part number	09 48 848 5745 015
Specification	VB RJ45 UaD -VB RJ45 LaR Cat.6A PUR 1.5m
HARTING eCatalogue	https://harting.com/09488485745015

Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING VarioBoot RJ45 Preferred directions up/down
Connector 2	HARTING VarioBoot RJ45 Preferred directions left/right
Type of cable	Copper cable (round)
Description of the cable	Wiring 1:1 Halogen-free Oil resistant

Version

Cable length	1.5 m
Number of cores	8
Core structure	4x 2 Twisted Pair

Technical characteristics

Transmission characteristics	Cat. 6A Class E _A up to 500 MHz
Data rate	10 Mbit/s 100 Mbit/s 1 Gbit/s 2.5 Gbit/s 5 Gbit/s 10 Gbit/s



Pushing Performance
Since 1945

Technical characteristics

Limiting temperature	-30 ... +75 °C unmoved
	-5 ... +50 °C moved
Degree of protection acc. to IEC 60529	IP20

Material properties

Material (cable)	PUR (polyurethane)
Colour (cable)	Yellow

Specifications and approvals

Specifications	ISO/IEC 11801
	IEC 61156-6

Commercial data

Packaging size	1
Net weight	76.2 g
Country of origin	Latvia
European customs tariff number	85444290
GTIN	5713140412088
eCl@ss	27060390 Ready-made data cable (unspecified)
ETIM	EC002599
UNSPSC 24.0	26121600