



Pushing Performance
Since 1945

DualBoot RJ45 FRNC Cat.5e yellow 25m

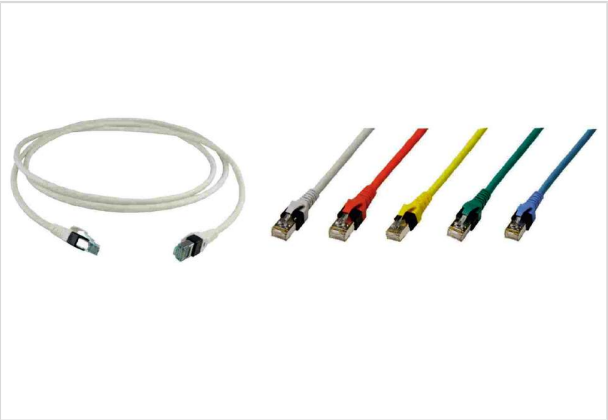


Image is for illustration purposes only. Please refer to product description.

Part number	09 48 868 6571 250
Specification	DualBoot RJ45 FRNC Cat.5e yellow 25m
HARTING eCatalogue	https://harting.com/09488686571250

Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING DualBoot RJ45
Connector 2	HARTING DualBoot RJ45
Type of cable	Copper cable (round)

Version

Cable length	25 m
Number of cores	8
Core structure	4x 2 Twisted Pair

Technical characteristics

Transmission characteristics	Cat. 5e Class D up to 100 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
Limiting temperature	-25 ... +60 °C unmoved
	0 ... +50 °C moved

Material properties

Material (cable)	FRNC (LSZH)
Colour (cable)	Yellow



Pushing Performance
Since 1945

Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Specifications and approvals

Specifications	ISO/IEC 11801
	EN 50173-1
	TIA/EI

Commercial data

Packaging size	1
Net weight	856.5 g
Country of origin	Latvia
European customs tariff number	85444290
GTIN	5713140253803
eCl@ss	27060308 Patch cord copper (data cable)
UNSPSC 24.0	26121609