

## DualBoot RJ45 FRNC Cat.5e green 20m

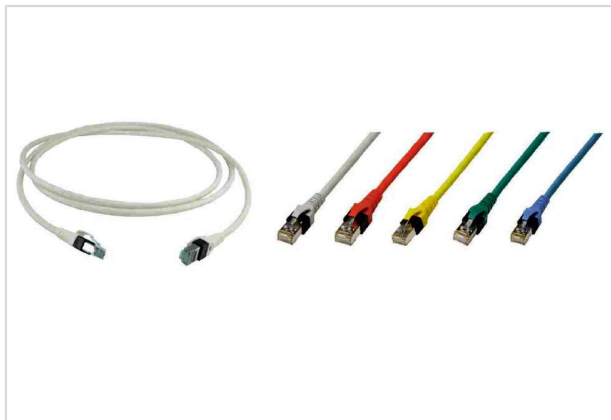


Image is for illustration purposes only. Please refer to product description.

Part number	09 48 868 6572 200
Specification	DualBoot RJ45 FRNC Cat.5e green 20m
HARTING eCatalogue	<a href="https://harting.com/09488686572200">https://harting.com/09488686572200</a>

### Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING DualBoot RJ45
Connector 2	HARTING DualBoot RJ45
Type of cable	Copper cable (round)

### Version

Cable length	20 m
Number of cores	8
Core structure	4x 2 Twisted Pair

### Technical characteristics

Transmission characteristics	Cat. 5e Class D up to 100 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
Limiting temperature	-25 ... +60 °C unmoved
	0 ... +50 °C moved

### Material properties

Material (cable)	FRNC (LSZH)
Colour (cable)	Green



Pushing Performance  
Since 1945

## Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	2-(2H-benzotriazol-2-yl)-4-(1,1,3,3-tetramethylbutyl)phenol (UV 329)
California Proposition 65 substances	Not contained

## Specifications and approvals

Specifications	ISO/IEC 11801
	EN 50173-1
	TIA/EI

## Commercial data

Packaging size	1
Net weight	830 g
Country of origin	Latvia
European customs tariff number	85444290
GTIN	5713140067929
eCl@ss	27060308 Patch cord copper (data cable)
UNSPSC 24.0	26121609