



Pushing Performance
Since 1945

DualBoot RJ45 FRNC Cat.5e blue 10m

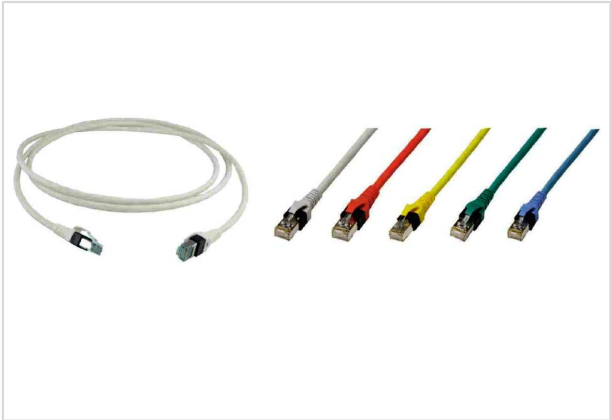


Image is for illustration purposes only. Please refer to product description.

Part number	09 48 868 6573 100
Specification	DualBoot RJ45 FRNC Cat.5e blue 10m
HARTING eCatalogue	https://harting.com/09488686573100

Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING DualBoot RJ45
Connector 2	HARTING DualBoot RJ45
Type of cable	Copper cable (round)

Version

Cable length	10 m
Number of cores	8
Core structure	4x 2 Twisted Pair

Technical characteristics

Transmission characteristics	Cat. 5e Class D up to 100 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
Limiting temperature	-25 ... +60 °C unmoved
	0 ... +50 °C moved

Material properties

Material (cable)	FRNC (LSZH)
Colour (cable)	Blue



Pushing Performance
Since 1945

Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	2-(2H-benzotriazol-2-yl)-4-(1,1,3,3-tetramethylbutyl)phenol (UV 329)
California Proposition 65 substances	Not contained

Specifications and approvals

Specifications	ISO/IEC 11801
	EN 50173-1
	TIA/EI

Commercial data

Packaging size	1
Net weight	355 g
Country of origin	Latvia
European customs tariff number	85444290
GTIN	5713140254084
eCl@ss	27060308 Patch cord copper (data cable)
UNSPSC 24.0	26121609