

DSUB LOOSE PART CRIMP CONTACT

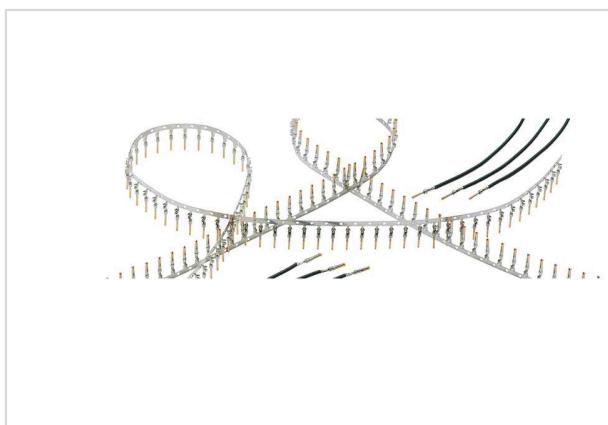


Image is for illustration purposes only. Please refer to product description.

Part number	09 67 000 8178
Specification	DSUB LOOSE PART CRIMP CONTACT
HARTING eCatalogue	https://harting.com/09670008178

Identification

Category	Contacts
Series	D-Sub
Identification	Standard
Type of contact	Crimp contact

Version

Termination method	Crimp termination
Gender	Male
Manufacturing process	Stamped contacts

Technical characteristics

Conductor cross-section	0.25 ... 0.52 mm ²
Conductor cross-section [AWG]	AWG 24 ... AWG 20
Wire outer diameter	≤1.52 mm
Contact resistance	≤10 mΩ
Stripping length	2.5 ... 3 mm
Performance level	2 acc. to CECC 75301-802
Mating cycles	≥250

Material properties

Material (contacts)	Copper alloy
RoHS	compliant

Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel

Commercial data

Packaging size	500
Net weight	0.1 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140087095
eCl@ss	27440204 Contact for industrial connectors
ETIM	EC000796
UNSPSC 24.0	39121522