

Han® ORV3 Power Bridge, Star Config.

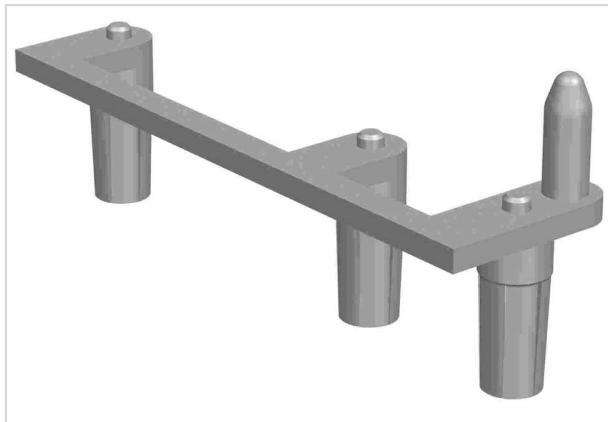


Image is for illustration purposes only. Please refer to product description.

Identification

Category	Accessories
Series	Han® ORV3 power
Type of accessory	Contact bridge
Description of the accessory	Configuration #01

Technical characteristics

Rated current	32 A
Rated voltage	480 V AC 380 V DC
Rated impulse voltage	6 kV
Pollution degree	3
Contact resistance	≤3 mΩ
Limiting temperature	-5 ... +45 °C
Mating cycles	≥100
Degree of protection acc. to IEC 60529	IP20

Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained

Material properties

REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

Specifications and approvals

Specifications	OCP V1.0
----------------	----------

Commercial data

Packaging size	10
Net weight	10.37 g
Country of origin	USA
European customs tariff number	85366990
GTIN	5713140445147
eCl@ss	27440392 Connector (accessories)
ETIM	EC002939
UNSPSC 24.0	39121400