

Han3A RJ45 Hybrid PFT housing

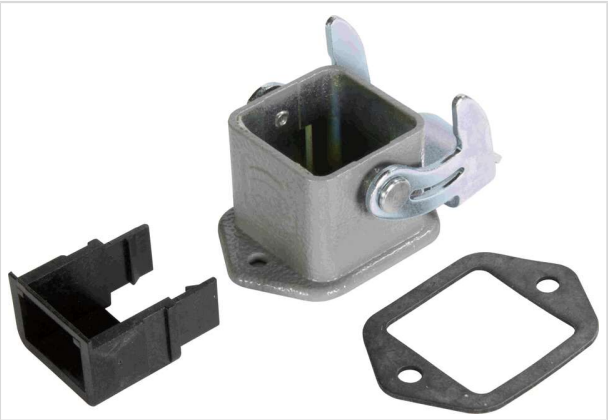


Image is for illustration purposes only. Please refer to product description.

Part number	10 12 005 1004
Specification	Han3A RJ45 Hybrid PFT housing
HARTING eCatalogue	https://harting.com/10120051004

Identification

Category	Accessories
Series of hoods/housings	Han® 3 A RJ45 Hybrid
Type of hood/housing	Bulkhead mounted housing
Description of hood/housing	incl. flat seal and thermoplastic adapter for direct device integration

Material properties

Material (hood/housing)	Metal
Colour (hood/housing)	Grey
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel

Commercial data

Packaging size	1
Net weight	32.89 g
Country of origin	Germany
European customs tariff number	85389099



Pushing Performance
Since 1945

Commercial data

GTIN	5713140108431
eCl@ss	27440202 Shell for industrial connectors
ETIM	EC000437
UNSPSC 24.0	39121466