

har-flex Board IDC 50p strain relief

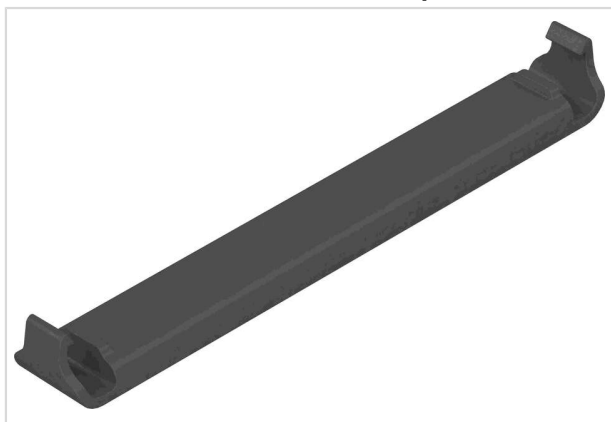


Image is for illustration purposes only. Please refer to product description.

Part number	15 39 050 0603 000
Specification	har-flex Board IDC 50p strain relief
HARTING eCatalogue	https://harting.com/15390500603000

Identification

Category	Accessories
Series	har-flex®
Identification	Board IDC
Type of accessory	Strain relief

Version

Number of contacts	50
--------------------	----

Technical characteristics

Limiting temperature	-55 ... +125 °C
Withdrawal force	>20 N

Material properties

Material (accessories)	Liquid crystal polymer (LCP)
Colour (accessories)	Black
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained



Pushing Performance
Since 1945

Material properties

California Proposition 65 substances	Not contained
--------------------------------------	---------------

Commercial data

Packaging size	600
Net weight	0.65 g
Country of origin	China
European customs tariff number	85366990
GTIN	5713140837430
eCl@ss	27440292 Connector component (accessories)
UNSPSC 24.0	39121400