

## Han INOX 3A Cover for Male in Housing

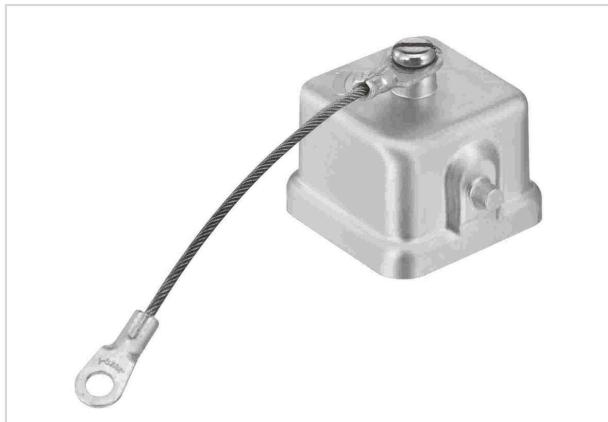


Image is for illustration purposes only. Please refer to product description.

Part number	19 44 003 5426
Specification	Han INOX 3A Cover for Male in Housing
HARTING eCatalogue	<a href="https://harting.com/19440035426">https://harting.com/19440035426</a>

### Identification

Category	Accessories
Series of hoods/housings	Han-INOX®
Type of accessory	Protection cover
Description of the accessory	for bulkhead mounted housings for surface mounted housings for cable to cable housing With fixing cord (cable shoe)

### Version

Size	3 A
Locking type	Single locking lever
Details	for mounted male insert

### Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP65 IP66 IP67
Type rating acc. to UL 50 / UL 50E	4 4X 12

### Material properties

Material (hood/housing)	Metal
Material (seal)	FPM

## Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

## Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076 CSA-C22.2 No. 182.3 ECBT8.E235076
Approvals	DNV GL

## Commercial data

Packaging size	1
Net weight	25.5 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140132047
eCl@ss	27440208 Cap for industrial connectors
ETIM	EC002314
UNSPSC 24.0	39121467