

Keystone Patch panel, unloaded

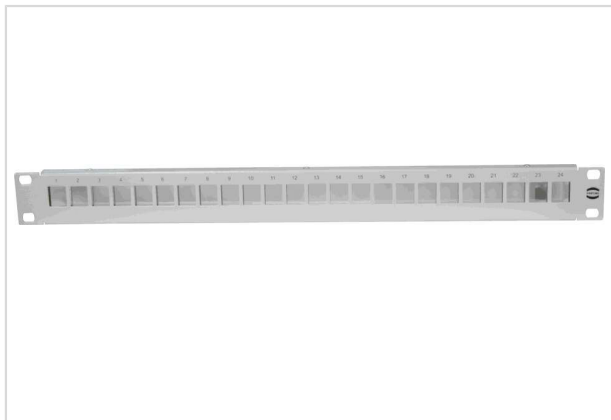


Image is for illustration purposes only. Please refer to product description.

Part number	20 82 400 0002
Specification	Keystone Patch panel, unloaded
HARTING eCatalogue	https://harting.com/20824000002

Identification

Category	Connectors
Series	preLink®
Element	Patch panel
Specification	Empty

Version

Size	Keystone version
Fixing	In 19" racks acc. to IEC/DIN EN 60 297-3-100 (DIN 41 494-1)

Technical characteristics

Transmission characteristics	Cat. 6 Class E up to 250 MHz
Data rate	10 Gbit/s
Limiting temperature	-40 ... +85 °C
Degree of protection acc. to IEC 60529	IP20
Vibration resistance	5.72 m/s ² acc. to IEC 61373 Category 1 Class B
Shock resistance	5 g / 30 ms, 5 shocks / axis and direction acc. to IEC 61373 Category 1 Class B

Material properties

Material (insert)	Steel sheet
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained



Pushing Performance
Since 1945

Material properties

REACH ANNEX XIV substances	Not contained
----------------------------	---------------

REACH SVHC substances	Not contained
-----------------------	---------------

Specifications and approvals

Specifications	EN 45545-2
----------------	------------

Approvals	DNV GL
-----------	--------

PROFINET	Yes
----------	-----

Commercial data

Packaging size	1
----------------	---

Net weight	950 g
------------	-------

Country of origin	Czechia
-------------------	---------

European customs tariff number	85389099
--------------------------------	----------

GTIN	5713140135710
------	---------------

eCl@ss	27440292 Connector component (accessories)
--------	--

ETIM	EC002943
------	----------

UNSPSC 24.0	39121400
-------------	----------