

## FO CABLE-MM 4G 50/125 10M,RING

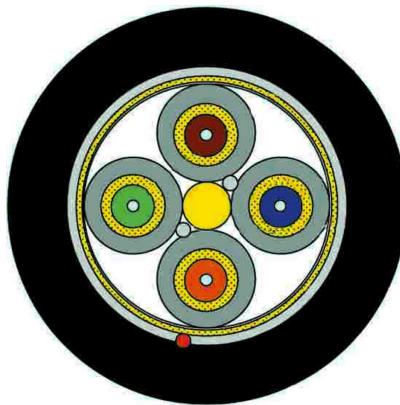


Image is for illustration purposes only. Please refer to product description.

Part number	33 54 751 0100 002
Specification	FO CABLE-MM 4G 50/125 10M,RING
HARTING eCatalogue	<a href="https://b2b.harting.com/33547510100002">https://b2b.harting.com/33547510100002</a>

### Identification

Category	System cabling
Element	Bulk cables
Specification	Not assembled
Type of cable	FO cable
Description of the cable	Multimode

### Version

Cable length	10 m
Core structure	50 / 125 $\mu$ m

### Technical characteristics

Cable diameter	8.2 mm
Minimum bending radius	13x Cable diameter (repeated bending) 10x Cable diameter (singular bending)

### Material properties

Material (cable)	FRNC (LSZH)
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained

## Material properties

REACH SVHC substances	Not contained
-----------------------	---------------

## Commercial data

Packaging size	1
Net weight	530 g
Net weight	66 g/m
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140795228
ETIM	EC000034
eCl@ss	27061803 Fiber optic cable