

FO CABLE-MM 4G 50/125 100M,RING

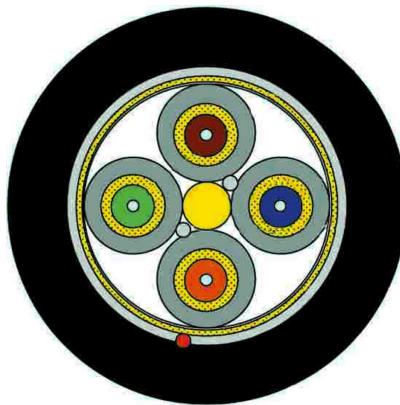


Image is for illustration purposes only. Please refer to product description.

Part number	33 54 751 1000 002
Specification	FO CABLE-MM 4G 50/125 100M,RING
HARTING eCatalogue	https://b2b.harting.com/33547511000002

Identification

Category	System cabling
Element	Bulk cables
Specification	Not assembled
Type of cable	FO cable
Description of the cable	Multimode

Version

Cable length	100 m
Core structure	50 / 125 μ m

Technical characteristics

Cable diameter	8.2 mm
Minimum bending radius	13x Cable diameter (repeated bending) 10x Cable diameter (singular bending)

Material properties

Material (cable)	FRNC (LSZH)
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained

Material properties

REACH SVHC substances	Not contained
-----------------------	---------------

Commercial data

Packaging size	1
Net weight	5,300 g
Net weight	66 g/m
Country of origin	Germany
European customs tariff number	85444995
GTIN	5713140795181
ETIM	EC000034
eCl@ss	27061803 Fiber optic cable