

InduCom 15p T&S-entry kn-screw 4-40 w/o

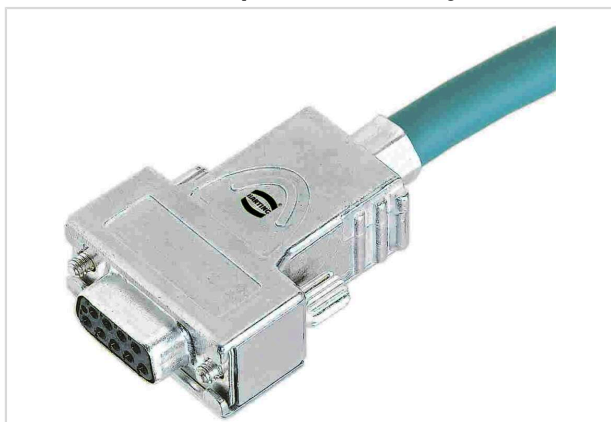


Image is for illustration purposes only. Please refer to product description.

Part number	61 03 001 0016 010
Specification	InduCom 15p T&S-entry kn-screw 4-40 w/o
HARTING eCatalogue	https://harting.com/61030010016010

Identification

Category	Hoods / Housings
Series	D-Sub
Identification	InduCom
Type of hood/housing	Shell housing
Description of hood/housing	Without internal earth

Version

Size	D-Sub 2
Version	Top entry
Number of cable entries	1
Cable entry	1x
Strain relief	An additional InduCom cable clamp or a crimp flange - ferrule combination is available dependant on the use of the cable.
Locking type	Knurled screw Thread 4-40 UNC
ground connection	Without internal grounding block
2 parts	Yes
Separable	Yes

Technical characteristics

Tightening torque	0.4 Nm cover screw 0.4 Nm Locking screw
Ambient temperature	-55 ... +125 °C
Degree of protection acc. to IEC 60529	IP30



Pushing Performance
Since 1945

Material properties

Material (hood/housing)	Zinc die-cast
Material (screw)	Steel, nickel plated
Length	34.7 mm
Width	39.5 mm
Height	14.8 mm
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Commercial data

Packaging size	10
Net weight	50 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140221659
eCl@ss	27440213 D-Sub hood
ETIM	EC001133
UNSPSC 24.0	39121416