

InduCom 15p T&S-entry kn-screw 4-40

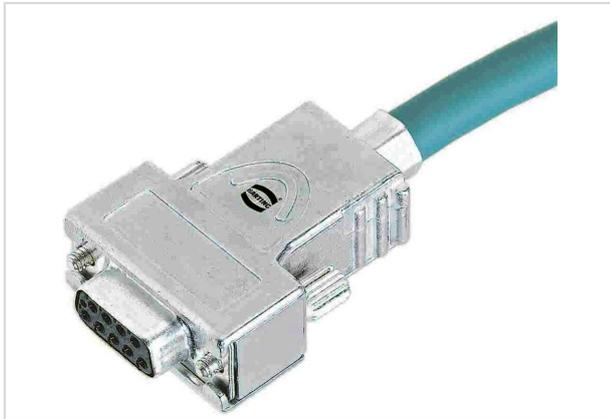


Image is for illustration purposes only. Please refer to product description.

Part number	61 03 001 0016
Specification	InduCom 15p T&S-entry kn-screw 4-40
HARTING eCatalogue	https://harting.com/61030010016

Identification

Category	Hoods / Housings
Series	D-Sub
Identification	InduCom
Type of hood/housing	Shell housing
Description of hood/housing	With internal earth

Version

Size	D-Sub 2
Version	Top entry
Number of cable entries	1
Cable entry	1x
Strain relief	An additional InduCom cable clamp or a crimp flange - ferrule combination is available dependant on the use of the cable.
Locking type	Knurled screw Thread 4-40 UNC
ground connection	With internal grounding block
2 parts	Yes
Separable	Yes

Technical characteristics

Tightening torque	0.4 Nm ground connection
	0.4 Nm cover screw
	0.4 Nm Locking screw
Ambient temperature	-20 ... +90 °C



Pushing Performance
Since 1945

Technical characteristics

Degree of protection acc. to IEC 60529	IP30
--	------

Material properties

Material (hood/housing)	Zinc die-cast
Material (screw)	Steel, nickel plated
Length	34.7 mm
Width	39.5 mm
Height	14.8 mm
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R26

Commercial data

Packaging size	1
Net weight	20 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140157651
eCl@ss	27440213 D-Sub hood
ETIM	EC001133
UNSPSC 24.0	39121416