

## InduCom 15p T&S-entry hexscrew 4-40

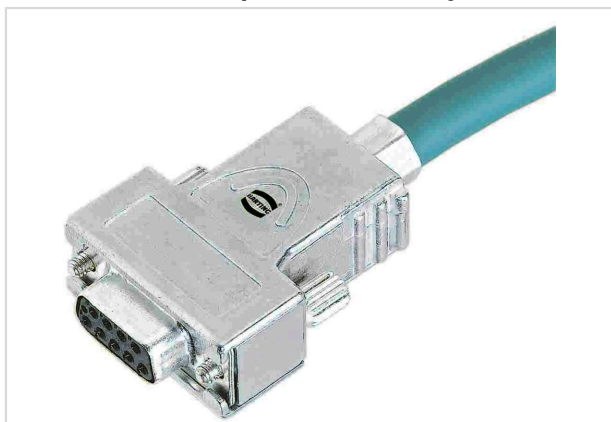


Image is for illustration purposes only. Please refer to product description.

Part number	61 03 001 2016
Specification	InduCom 15p T&S-entry hexscrew 4-40
HARTING eCatalogue	<a href="https://harting.com/61030012016">https://harting.com/61030012016</a>

### Identification

Category	Hoods / Housings
Series	D-Sub
Identification	InduCom
Type of hood/housing	Shell housing
Description of hood/housing	With internal earth

### Version

Size	D-Sub 2
Version	Top entry
Number of cable entries	1
Cable entry	1x
Strain relief	An additional InduCom cable clamp or a crimp flange - ferrule combination is available dependant on the use of the cable.
Locking type	Hexagonal screw with captive washer Thread 4-40 UNC
ground connection	With internal grounding block
2 parts	Yes
Separable	Yes

### Technical characteristics

Tightening torque	0.4 Nm ground connection
	0.4 Nm cover screw
	0.4 Nm Locking screw
Ambient temperature	-20 ... +90 °C



Pushing Performance  
Since 1945

## Technical characteristics

Degree of protection acc. to IEC 60529	IP30
--	------

## Material properties

Material (hood/housing)	Zinc die-cast
Material (screw)	Steel, nickel plated
Length	34.7 mm
Width	39.5 mm
Height	14.8 mm
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R26

## Commercial data

Packaging size	1
Net weight	30 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140157934
eCl@ss	27440213 D-Sub hood
ETIM	EC001133
UNSPSC 24.0	39121416