

## InduCom 25p T&S-entry hexscrew 4-40

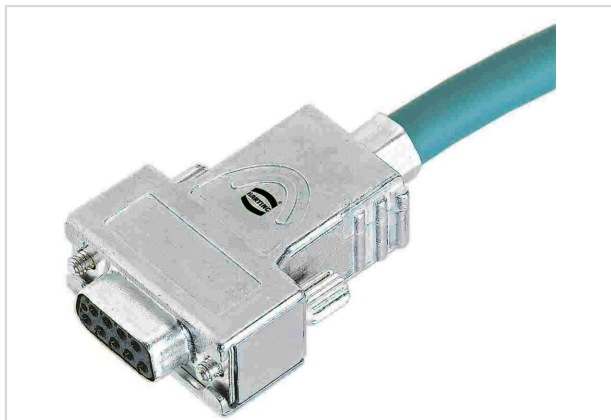


Image is for illustration purposes only. Please refer to product description.

Part number	61 03 001 2017
Specification	InduCom 25p T&S-entry hexscrew 4-40
HARTING eCatalogue	<a href="https://harting.com/61030012017">https://harting.com/61030012017</a>

### Identification

Category	Hoods / Housings
Series	D-Sub
Identification	InduCom
Type of hood/housing	Shell housing
Description of hood/housing	With internal earth

### Version

Size	D-Sub 3
Version	Top/side entry
Number of cable entries	3
Cable entry	3x
Strain relief	An additional InduCom cable clamp or a crimp flange - ferrule combination is available dependant on the use of the cable.
Locking type	Hexagonal screw with captive washer Thread 4-40 UNC
ground connection	With internal grounding block
2 parts	Yes
Separable	Yes
Details	Part number includes two dummy plugs

### Technical characteristics

Tightening torque	0.4 Nm ground connection
	0.4 Nm cover screw
	0.4 Nm Locking screw
Ambient temperature	-20 ... +90 °C



**Pushing Performance**  
Since 1945

## Technical characteristics

Degree of protection acc. to IEC 60529	IP30
--	------

## Material properties

Material (hood/housing)	Zinc die-cast
Material (screw)	Steel, nickel plated
Length	42.4 mm
Width	53 mm
Height	14.8 mm
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R26

## Commercial data

Packaging size	1
Net weight	57 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140157941
eCl@ss	27440213 D-Sub hood
ETIM	EC001133
UNSPSC 24.0	39121416