

InduCom 9p 1T-entry kn-screw M3 w/o

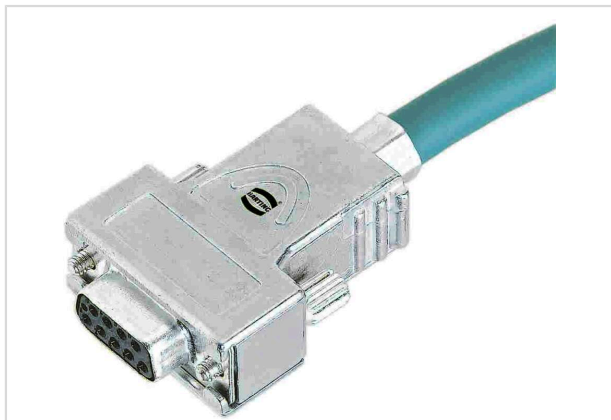


Image is for illustration purposes only. Please refer to product description.

Part number	61 03 001 3010 010
Specification	InduCom 9p 1T-entry kn-screw M3 w/o
HARTING eCatalogue	https://harting.com/61030013010010

Identification

Category	Hoods / Housings
Series	D-Sub
Identification	InduCom
Type of hood/housing	Shell housing
Description of hood/housing	Without internal earth

Version

Size	D-Sub 1
Version	Top entry
Number of cable entries	1
Cable entry	1x
Strain relief	An additional InduCom cable clamp or a crimp flange - ferrule combination is available dependant on the use of the cable.
Locking type	Knurled screw Thread M3
ground connection	Without internal grounding block
2 parts	Yes
Separable	Yes

Technical characteristics

Tightening torque	0.4 Nm cover screw
	0.4 Nm Locking screw
Ambient temperature	-55 ... +125 °C
Degree of protection acc. to IEC 60529	IP30



Pushing Performance
Since 1945

Material properties

Material (hood/housing)	Zinc die-cast
Material (screw)	Steel, nickel plated
Length	36.9 mm
Width	31 mm
Height	14.8 mm
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R26

Commercial data

Packaging size	10
Net weight	36 g
Country of origin	Hungary
European customs tariff number	85389099
GTIN	5713140158009
eCl@ss	27440213 D-Sub hood
ETIM	EC001133
UNSPSC 24.0	39121416