



Pushing Performance
Since 1945

InduCom 37p T&S-entry kn-screw M3

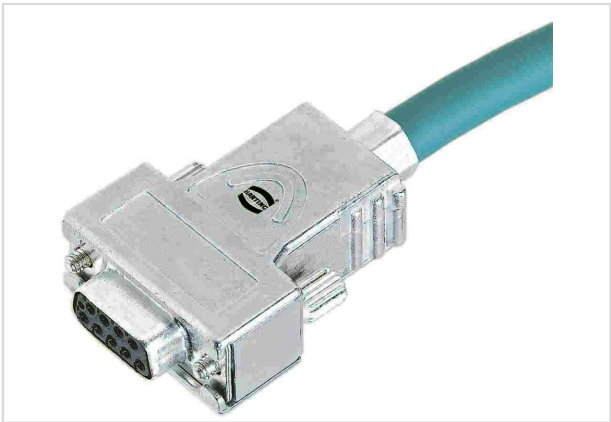


Image is for illustration purposes only. Please refer to product description.

Part number	61 03 001 3018
Specification	InduCom 37p T&S-entry kn-screw M3
HARTING eCatalogue	https://harting.com/61030013018

Identification

Category	Hoods / Housings
Series	D-Sub
Identification	InduCom
Type of hood/housing	Shell housing
Description of hood/housing	With internal earth

Version

Size	D-Sub 4
Version	Top/side entry
Number of cable entries	3
Cable entry	3x
Strain relief	An additional InduCom cable clamp or a crimp flange - ferrule combination is available dependant on the use of the cable.
Locking type	Knurled screw Thread M3
ground connection	With internal grounding block
2 parts	Yes
Separable	Yes
Details	Part number includes two dummy plugs

Technical characteristics

Tightening torque	0.4 Nm ground connection
	0.4 Nm cover screw
	0.4 Nm Locking screw
Ambient temperature	-20 ... +90 °C



Pushing Performance
Since 1945

Technical characteristics

Degree of protection acc. to IEC 60529	IP30
--	------

Material properties

Material (hood/housing)	Zinc die-cast
Material (screw)	Steel, nickel plated
Length	42.4 mm
Width	69.5 mm
Height	14.8 mm
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R26

Commercial data

Packaging size	1
Net weight	86 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140158061
eCl@ss	27440213 D-Sub hood
ETIM	EC001133
UNSPSC 24.0	39121416