

## Han DDD55\_AC\_PCB-Adpt\_PC\_f.Insert

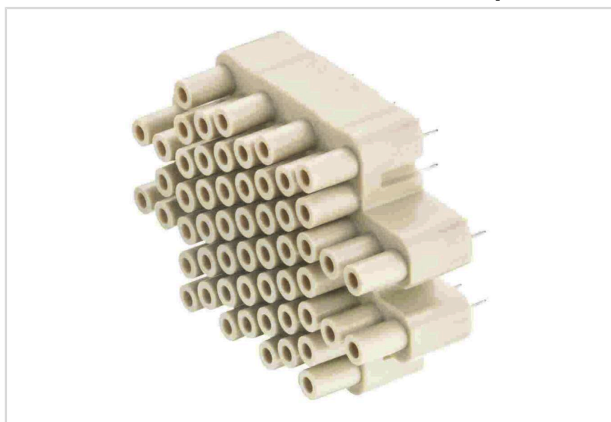


Image is for illustration purposes only. Please refer to product description.

Part number	97 00 000 0752
Specification	Han DDD55_AC_PCB-Adpt_PC_f.Insert
HARTING eCatalogue	<a href="https://harting.com/97000000752">https://harting.com/97000000752</a>

### Identification

Category	Accessories
Type of accessory	PCB adapter
Description of the accessory	In the Han <sup>®</sup> 55 DDD crimp insert

### Version

Gender	Male Female
Details	for PCB's up to 1.6 mm

### Technical characteristics

Rated current	7.5 A
Rated voltage	250 V
Rated impulse voltage	4 kV
Pollution degree	2
Limiting temperature	-40 ... +125 °C

### Material properties

Material (insert)	Polycarbonate (PC)
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained



**Pushing Performance**  
Since 1945

## Material properties

REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

## Specifications and approvals

Specifications	IEC 61984
UL / CSA	UL 1977 ECBT2.E235076 CSA-C22.2 No. 182.3 ECBT8.E235076

## Commercial data

Packaging size	10
Net weight	23.6 g
European customs tariff number	85366990
eCl@ss	27460201 PCB connector (board connector)
UNSPSC 24.0	39121415