
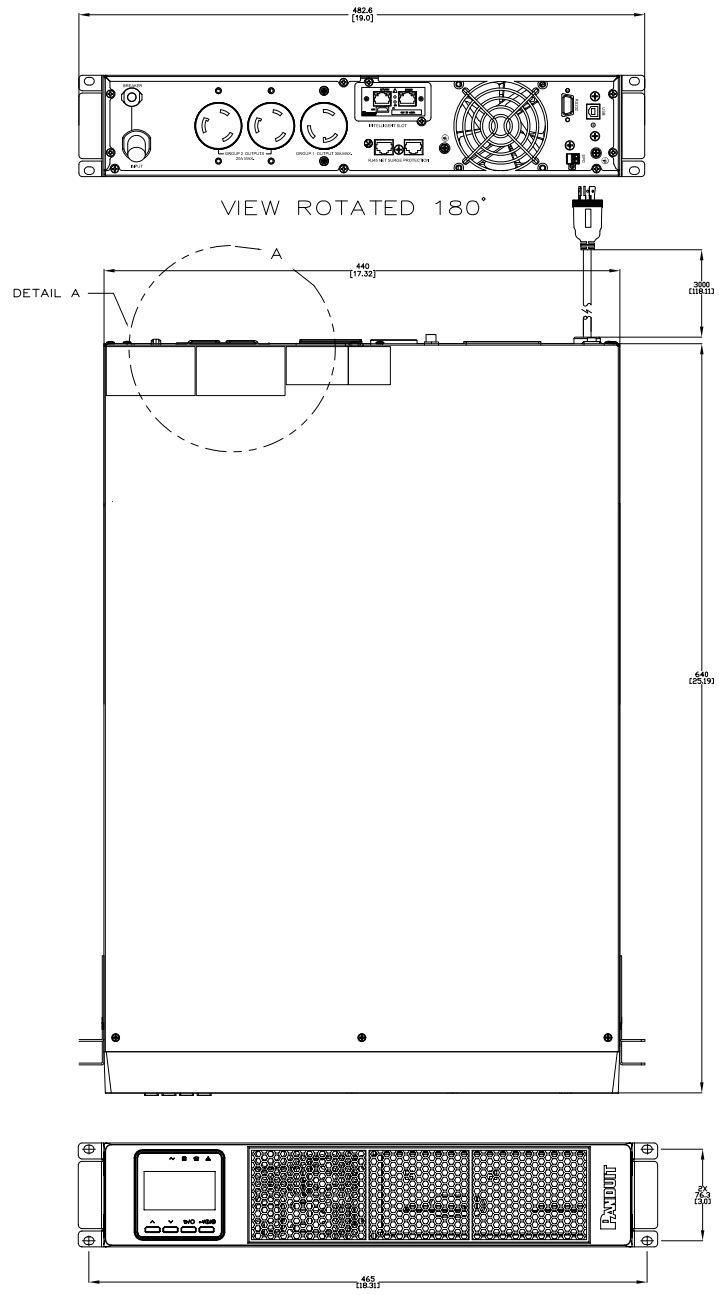


- SPECIFICATION:**
- 1. STANDARD:**
- UPS TOPOLOGY:** DOUBLE CONVERSION
- KVA:** 3
- BATTERY TYPE:** LITHIUM-ION
- FULL-LOAD RUN TIME (MIN):** 9 MINUTES
- INPUT PLUG:** NEMA L6-20P
- NOMINAL INPUT VOLTAGE:** 208/240VAC
- INPUT PHASE:** SINGLE
- OUTPUT PHASE:** SINGLE
- NOMINAL OUTPUT VOLTAGE:** 208/240VAC
- OUTLET TYPE AND QTY:** 2.8 INCH, 4 BUTTON
- DISPLAY TYPE:** NO
- PARALLEL PORT SUPPORT:** 25A PUSH BUTTON
- INPUT BREAKER TYPE:** N/A
- OUTPUT BREAKER TYPE:** N/A
- 2. ADDITIONAL:** NONE
- 3. ACCESSORY COMPONENTS:**
- P/N U03N11L-H CONTAINS AN INTELLIGENT NETWORK CARD,(INSTALLED)
- STABILIZER BRACKET(WITH RUBBER CUSHION),QTY:(4)
- INSTALLATION EARS,QTY:(2)
- SAFETY WARNING SHEET,QTY:(1)
- DOCUMENTATION KIT, QTY(1)
- INCLUDES P/N:ULC372 INTERNAL BATTERY CARTRIDGE, QTY:(1),(INSTALLED)
- INCLUDES P/N:URMKIT2 INSTALLATION RAIL KIT, QTY:(1),(U03N15L ONLY)
- REFER TO ASSOCIATED DRAWINGS FOR PHYSICAL DIMENSIONS AND SPECIFICATIONS
- EPO PLUG WITH SHORTING WIRE,QTY:(1),(INSTALLED)

- NOTES:**
1. PRIMARY DIMENSIONS ARE IN MILLIMETERS. SECONDARY DIMENSIONS ARE IN INCHES
2. INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL,STATE,AND LOCAL CODES
3. VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PRODUCT

IDENTIFICATION:		
PART NUMBER	DESCRIPTION	SHIPPING WEIGHT (KG)
U03S15L	UPS, 3kVA, 2U, 208V, SINGLE PHASE, LITHIUM-ION, DOUBLE-CONVERSION ON-LINE POWER PROTECTION	25.4
U03N15L	UPS, 3kVA, 2U, 208V, SINGLE PHASE, LITHIUM-ION, DOUBLE-CONVERSION ON-LINE POWER PROTECTION WITH INTELLIGENT NETWORK CARD	28.6

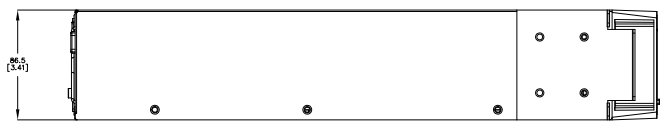

TITLE									
UPS									
U03S15L/U03N15L									
CUSTOMER DRAWING									
PANDUIT									
N/A									
U03N15L-DC									
SHT 1 OF 2									
REV									
00A	12/30/2024	DL	URM	M.B./BROD	RELEASE TO PRODUCTION	U03N15L	ECN	THIRD ANGLE PROJECTION	U03N15L-DC
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN	DATE	FILE	VARIOUS
00A	12/30/2024	DL	URM	M.B./BROD	RELEASE TO PRODUCTION	U03N15L	12/30/2024	FILE	VARIOUS

PANDUIT

18900 PANDUIT DRIVE, 60487, USA
WWW.PANDUIT.COM

UNINTERRUPTIBLE POWER SYSTEMS

MODEL NUMBER: U03N15L
INPUT: 208/240 VAC 1 50/60Hz 1 16.0 A Max. 1 1PH+N+PE
BATTERY INPUT: ≤84 V — 45 A
BATTERY CAPACITY/ENERGY: 76.8 V / 9 Ah / 691.2 Wh

OUTPUT: 208/240 VAC 1 50/60Hz 1 1PH+N+PE
3000VA/2700W, 14.5A (@208VAC input)
3000VA/2700W, 12.5A (@240VAC input)
Icc: 3 kA

PROHIBIDO SU USO EN EXTERIORES
MADE IN xxx
HECHO EN xxx



UPS MODULE
U03S15L/U03N15L
1PH,208/240VAC OUTPUT

UTILITY POWER CORE
CONNECTION

INPUT CIRCUIT
BREAKER

INPUT RELAY

OUTPUT RELAY

OUTPUT SOCKET PANEL

ED2 RELAY

G2 OUTLET
RECEPTACLE

 
G1 OUTLET
RECEPTACLE

INTERNAL LITHIUM-ION

LEGEND



CIRCUIT BREAKER



RELAY



AC-DC CONVERTER



DC-AC CONVERTER
(INVERTER)



AC-DC CHARGE



BATTERY

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
00A					SEE SHEET 1 FOR CHANGES	

TYPE UPS U03S15L/U03N15L CUSTOMER DRAWING	
PAK NUMBER NAME U03S15L/U03N15L/00	EXTERNAL N/A
POINT-TO-POINT NAME U03S15L/U03N15L-DC/00A	EXTERNAL U03N15L-DC
UNLESS OTHERWISE SPECIFIED DIMENSIONAL TOLERANCES AND FIN (IN)	
PRINTED DATE D.L. 12/30/2024	THIRD ANGLE PROJECTION VARIOUS
DATE / DIM	SHT 2 OF 2