

HC-B-SG-PL-BK - Strain relief



1424343

<https://www.phoenixcontact.com/us/products/1424343>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Strain relief, design: B6 - B24



Commercial data

Item number	1424343
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF60
Product key	AF7AHZ
GTIN	4055626370804
Weight per piece (including packing)	22.9 g
Weight per piece (excluding packing)	22.9 g
Customs tariff number	85389099
Country of origin	CN

HC-B-SG-PL-BK - Strain relief

1424343

<https://www.phoenixcontact.com/us/products/1424343>



Technical data

Product properties

Product type	Strain relief
--------------	---------------

Material specifications

Material	PA
Flammability rating according to UL 94	V0

HC-B-SG-PL-BK - Strain relief


1424343

<https://www.phoenixcontact.com/us/products/1424343>



Drawings

Dimensional drawing

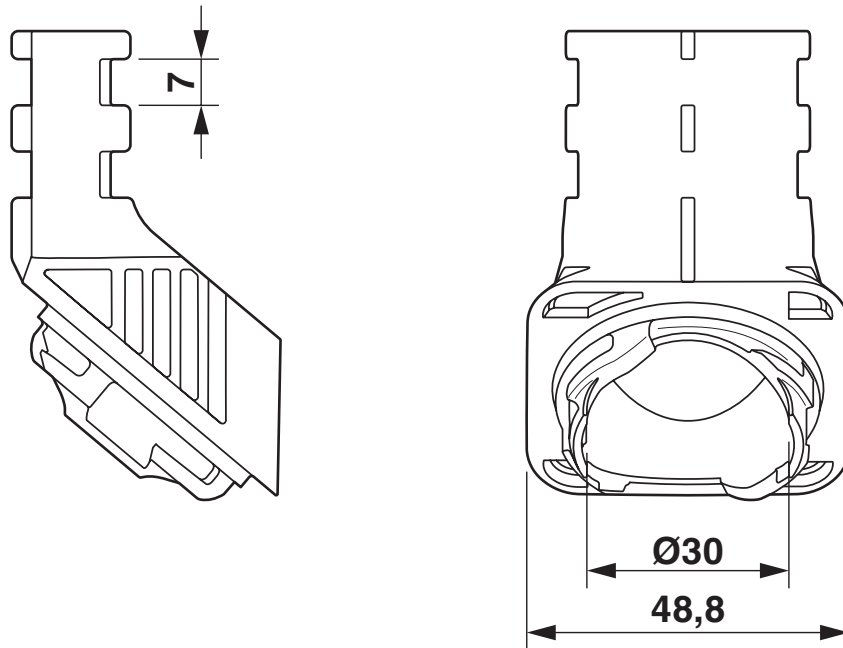

Dimensional drawing

HC-B-SG-PL-BK - Strain relief



1424343

<https://www.phoenixcontact.com/us/products/1424343>

Classifications

ECLASS

ECLASS-15.0	27440192
ECLASS-13.0	27440192

ETIM

ETIM 9.0	EC002943
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

HC-B-SG-PL-BK - Strain relief



1424343

<https://www.phoenixcontact.com/us/products/1424343>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%
EF3.0 Climate Change	
CO2e kg	0.295 kg CO2e

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com