

HC-DS-PG36-Z - Pressure screw

1772667

<https://www.phoenixcontact.com/us/products/1772667>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Pressure screws, with strain relief clamps, nickel-plated brass, clamping area 25.5 mm ... 34 mm, type Pg36



Commercial data

Item number	1772667
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	BF68
Product key	AF7DFX
GTIN	4017918037321
Weight per piece (including packing)	166.72 g
Weight per piece (excluding packing)	166.72 g
Customs tariff number	74153300
Country of origin	DE

HC-DS-PG36-Z - Pressure screw

1772667

<https://www.phoenixcontact.com/us/products/1772667>



Technical data

Product properties

Product type	Half screw connection
Pg screw connection	Pg36

Dimensions

Dimensional drawing	
Wrench size, union nut	52 mm
Clamping range of the strain relief clip	26.00 mm ... 34.00 mm

Material specifications

Material Pressure screw	Brass, nickel-plated
-------------------------	----------------------

HC-DS-PG36-Z - Pressure screw


1772667

<https://www.phoenixcontact.com/us/products/1772667>



Drawings

Dimensional drawing

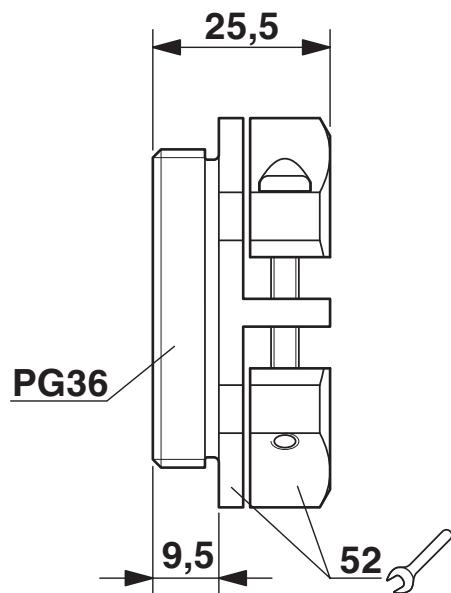

Dimensional drawing

HC-DS-PG36-Z - Pressure screw

1772667

<https://www.phoenixcontact.com/us/products/1772667>



Classifications

UNSPSC

UNSPSC 21.0

31161514

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com