

# BMKL 15X 9 WH - Label sheet, DIN A4



0803663

<https://www.phoenixcontact.com/us/products/0803663>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Label sheet, DIN A4, Sheet, white, unmarked, can be labeled with: PLOTMARK, CMS-P1-PLOTTER, Office printing systems, mounting type: adhesive, Number of individual labels: 290, text field height: 9 mm, text field width: 15 mm



## Your advantages

- These labels have been specially developed for laser printers
- Labeling service: Phoenix Contact can custom-label all BMKL ... markers according to your requirements
- Can be printed on all commercially available laser printers
- The material file can be downloaded under the CLIP PROJECT software under Downloads - "Software update - Marking"
- The unperforated SK-U... sheets are available for custom label designs

## Commercial data

Item number	0803663
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BG13
Product key	BG2414
GTIN	4017918007621
Weight per piece (including packing)	14.68 g
Weight per piece (excluding packing)	14.28 g
Customs tariff number	39199080
Country of origin	DE

# BMKL 15X 9 WH - Label sheet, DIN A4

0803663

<https://www.phoenixcontact.com/us/products/0803663>



## Technical data

### Product properties

Product type	Gerätemarker
<b>Marking</b>	
Number of individual labels	290
Number of individual labels per row	10
Identification technology	Office laser printing

### Mounting

Mounting type	adhesive
<b>Material specifications</b>	

### Material specifications

Color	white (RAL 9010)
Material	Polyester
Base element material	Polyester
Components	Silicone-free

### Environmental and real-life conditions

<b>Ambient conditions</b>	
Ambient temperature (operation)	-20 °C ... 80 °C
Recommended ambient temperature (storage/transport)	20 °C ... 25 °C
Recommended humidity (storage/transport)	40 % ... 50 %
Shelf life	2 years

### Dimensions

Width	9.00 mm
Height	15.00 mm
Depth	0.09 mm

### Standards and regulations

Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
<b>Notes</b>	

General	Print image may vary depending on laser printer
<b>Page footer</b>	

# BMKL 15X 9 WH - Label sheet, DIN A4


0803663

<https://www.phoenixcontact.com/us/products/0803663>



## Drawings

Dimensional drawing

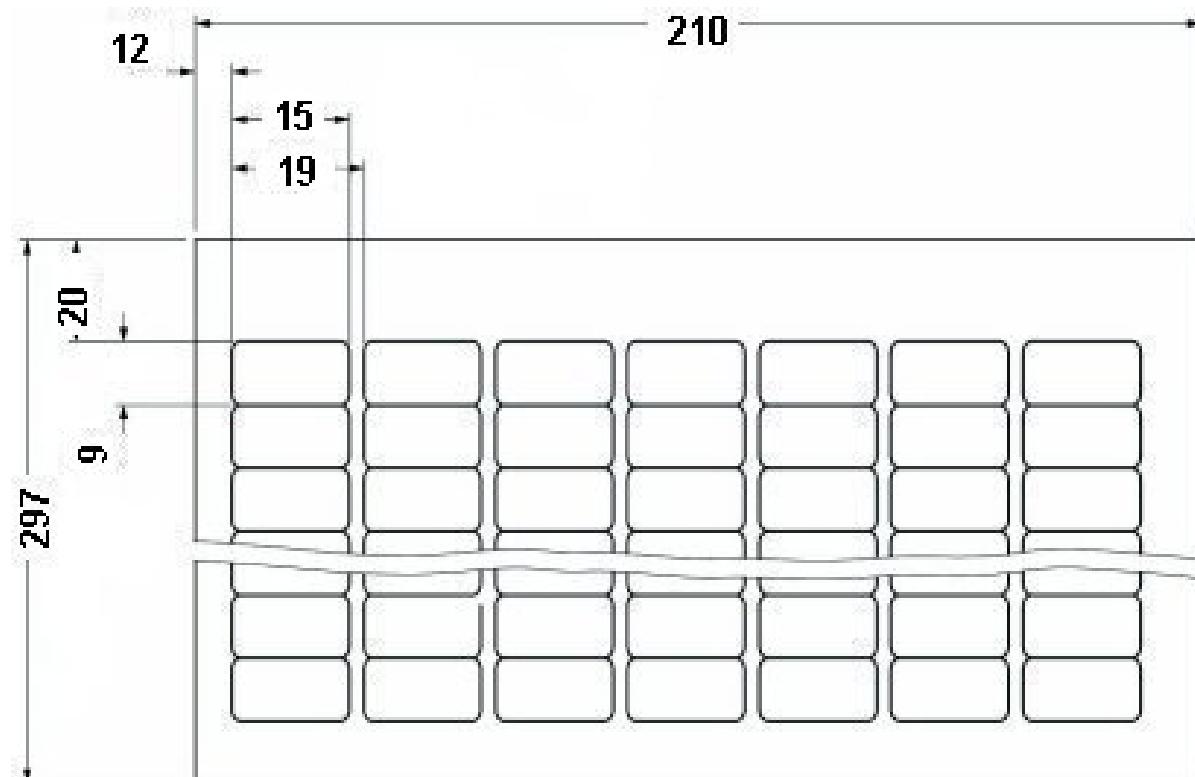

# BMKL 15X 9 WH - Label sheet, DIN A4

0803663

<https://www.phoenixcontact.com/us/products/0803663>



## Classifications

### ECLASS

ECLASS-13.0	27281103
ECLASS-15.0	27281103

### ETIM

ETIM 9.0	EC001288
----------	----------

### UNSPSC

UNSPSC 21.0	39131500
-------------	----------

# BMKL 15X 9 WH - Label sheet, DIN A4

0803663

<https://www.phoenixcontact.com/us/products/0803663>



## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA

586 Fulling Mill Road

Middletown, PA 17057, United States

(+717) 944-1300

[info@phoenixcon.com](mailto:info@phoenixcon.com)