


# SFL (2,8-0,8)D32 - Female connector strip



2285302

<https://www.phoenixcontact.com/us/products/2285302>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

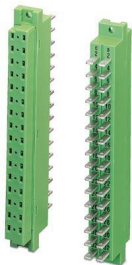

19" socket strip, color: green, number of positions: 32, product range: SFL (2,8-0,8), pitch: 0 mm, type of packaging: packed in cardboard

## Commercial data

|                                      |                                |
|--------------------------------------|--------------------------------|
| Item number                          | 2285302                        |
| Packing unit                         | 10 pc                          |
| Minimum order quantity               | 10 pc                          |
| Note                                 | Made to order (non-returnable) |
| Sales key                            | AA08                           |
| Product key                          | AAHHCA                         |
| GTIN                                 | 4017918055905                  |
| Weight per piece (including packing) | 30.05 g                        |
| Weight per piece (excluding packing) | 28.71 g                        |
| Customs tariff number                | 85369010                       |
| Country of origin                    | PL                             |

# SFL (2,8-0,8)D32 - Female connector strip



2285302

<https://www.phoenixcontact.com/us/products/2285302>

## Technical data

### Product properties

|                     |                  |
|---------------------|------------------|
| Product type        | 19" socket strip |
| Product family      | SFL (2,8-0,8)    |
| Type                | D                |
| Number of positions | 32               |
| Pitch               | 0 mm             |

### Electrical properties

|                             |        |
|-----------------------------|--------|
| Rated surge voltage (III/3) | 2.5 kV |
|-----------------------------|--------|

### Connection data

|                   |                  |
|-------------------|------------------|
| Connection method | Spade connection |
|-------------------|------------------|

### Dimensions

|                     |         |
|---------------------|---------|
| Dimensional drawing |         |
| Width               | 95 mm   |
| Height              | 27.6 mm |
| Length              | 10.6 mm |
| Hole diameter       | 2.8 mm  |
| Pitch               | -       |

### Material specifications

|                                        |                  |
|----------------------------------------|------------------|
| Color (Housing)                        | green (RAL 6021) |
| Flammability rating according to UL 94 | HB               |
| Insulating material group              | II               |
| Insulating material                    | PA-F             |
| Contact surface                        | Tin Sn           |

### Packaging specifications

|                   |                     |
|-------------------|---------------------|
| Type of packaging | packed in cardboard |
|-------------------|---------------------|


# SFL (2,8-0,8)D32 - Female connector strip

2285302

<https://www.phoenixcontact.com/us/products/2285302>



## Drawings

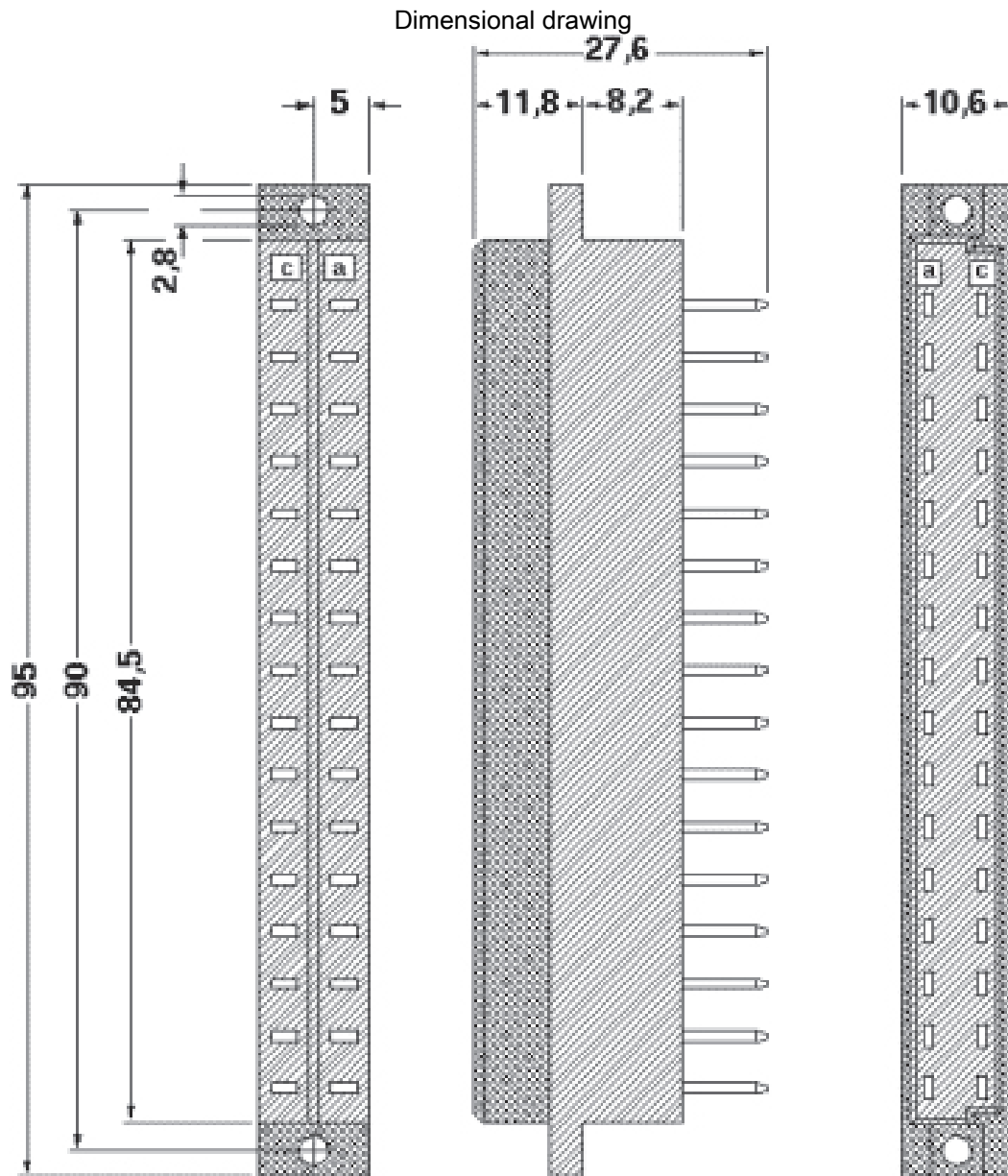

# SFL (2,8-0,8)D32 - Female connector strip



2285302

<https://www.phoenixcontact.com/us/products/2285302>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27460101 |
| ECLASS-15.0 | 27460101 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC002643 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

# SFL (2,8-0,8)D32 - Female connector strip



2285302

<https://www.phoenixcontact.com/us/products/2285302>

## Environmental product compliance

### EU RoHS

|                                         |                    |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

### China RoHS

|                                        |                                          |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|                                        | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)